




Plates, Wall Phone, 6-Position 4-Conductor, 110 Block, White

By Hubbell Wiring Device-Kellems
Catalog # [NS721W](#)

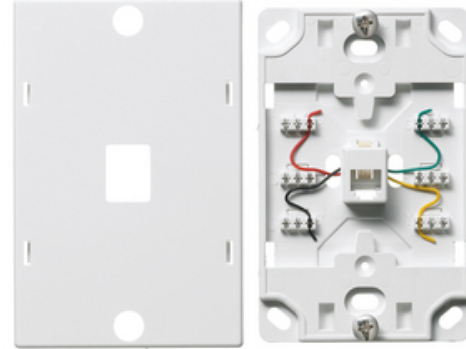

Plates, Wall Phone, 6-Position 4- Conductor, 110 Block, White

Features

- Meets FCC part 68
- Available in high impact-resistant thermoplastic or stainless steel

Application

Communications

General

Color	White
Contact	Phosphor Bronze
EU RoHS Indicator	Yes
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	1) 6-Position 4-Conductor Jack
Material	Nylon
Material - Mounting Hardware	Screw Mounting
Size	Standard
Temperature Rating	Max Continuous- 75 Degrees C, Minimum- -40 Without Impact
Type	Telephone Jack
UPC	883778502613

Dimensions

Display Size Standard Sized Product

Electrical Ratings

Connectivity	110 Punch Down
Contact Resistance	Per TIA
Insertion Loss	Per TIA

Certifications and Compliance

Industry Standard(s) UL Listed

Logistics

Carton Quantity 10

Product Assets

[Engineering Drawing - NS721W AutoCAD Drawing](#)
[Sales Drawings - WDK_NS721_DRAWING_PDF](#)
[Warranty - Industrial & Commercial Products](#)

Related Products

[NS723SS - Wall Phone Plate, 6-Position 4- Conductor, 110 Terminals, Stainless Steel](#)
[NS721I - Plates, Wall Phone, 6-Position 4- Conductor, 110 Block, Electric Ivory](#)



A proud member of the Hubbell Family.