




Wiring Device-Kellems

Net Select, Snap-Fit, With F Connector, Ivory

By Hubbell Wiring Device-Kellems
Catalog # [NSF70I](#)

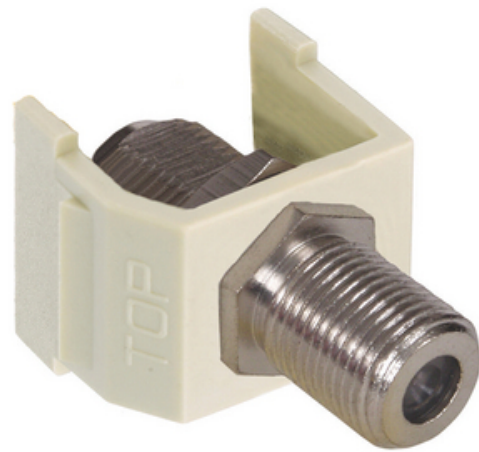

Net Select, Snap-Fit, With F Connector, Ivory

Features

- Universal keystone design
- Seamless Hubbell system integration
- Quick and easy screw-style installation

Application

CATV

General

Contact	Phosphor Bronze
EU RoHS Indicator	Yes
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	1) Nickel F-Coax Connector
Material - Mounting Hardware Style	Screw Mounting Coupler
Temperature Rating	Max Continuous- 75 Degrees C, Minimum- -40 Without Impact
Type	F-Type
UPC	883778503290

Dimensions

Display Size Standard Sized Product

Electrical Ratings

Connectivity	Female to Female
Contact Resistance	Per TIA
Insertion Loss	Per TIA

Logistics

Carton Quantity 25

Product Assets

- [Catalog Page - PREM S9 CatalogPage](#)
- [Catalog Page - WDK Y-6 Catalog Page](#)
- [Catalog Page - WDK Z-10 Catalog Page](#)
- [Catalogs - Premise Wiring Catalog](#)
- [Catalogs - WDK Catalog Full 2024](#)
- [Engineering Drawing - NSF70I AutoCAD Drawing](#)
- [Sales Drawings - WDK_NSF70_DRAWING_PDF](#)
- [Warranty - Industrial & Commercial Products](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.
WDK-NSF70I-SPEC-EN | REV 5/2024