


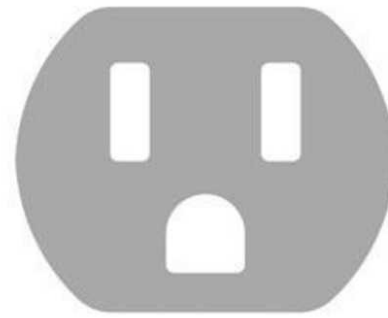

Wiring Device-Kellems

Signal And Control, Linkosity, Cordset, Female, Double End, 90 Degree, 3-Wire, 10A 600V AC, PB Wire Code, 10' Length, Stainless Hex Nuts

By Hubbell Wiring Device-Kellems
Catalog # [PG1003PB010S](#)



Oh No!
IMAGE COMING SOON

Signal And Control, Linkosity, Cordset, Female, Double End, 90 Degree, 3-Wire, 10A 600V AC, PB Wire Code, 10' Length, Stainless Hex Nuts

Application

Quick Connect/Disconnect Signal and Control

General

Color	Gray
Construction	Fabricated
EU RoHS Indicator	Yes
Insulation	PVC
Item Type	Single Ended Cable, 90 Degree Female Connector
OEM Brand Name	Hubbell Wiring Device-Kellems
Plug Type	Linkosity
Temperature Rating	-20 Deg C to 105 Deg C
UPC	783585184807

Dimensions

Outside Diameter	0.71
------------------	------

Electrical Ratings

Amperage Rating	10 A
Current / Amperage Rating	10 A
Current Rating	10 A
Voltage Rating	600V kV

Conductor Related

Conductor Size	#12 AWG
Conductor Type	Copper
Number Of Conductors	3-Pole
Strands	Multi

Logistics

Carton Quantity	10
-----------------	----

Product Assets

- [Installation Manuals - WIRING_PD2038_INSTALLINST](#)
- [Literature - WIRING_WLFVM034](#)
- [Literature - Linkosity Wiring System](#)
- [Literature - Pulp & Paper Solutions](#)
- [Warranty - Industrial & Commercial Products](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
WDK-PG1003PB010S-SPEC-EN | REV 5/2023