




Wiring Device-Kellems

Linkosity, 10A, 2W, Female Receptacle, 1'

By Hubbell Wiring Device-Kellems
Catalog # [RF1002PE001](#)

Linkosity, 10A, 2W, Female Receptacle, 1'

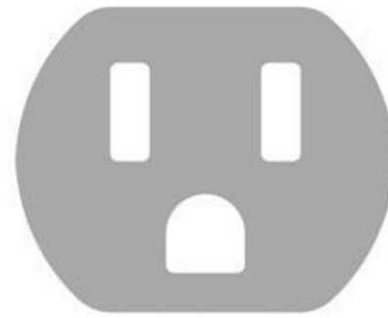

Oh No!
IMAGE COMING SOON

Application

Power and Control Integration

General

Color	Gray
Construction	Fabricated
EU RoHS Indicator	Yes
Item Type	Female Receptacle
Material	Composite
Number Of Poles	2-Pole
OEM Brand Name	Hubbell Wiring Device-Kellems
UPC	783585504353

Electrical Ratings

Amperage Rating	10 A
Current / Amperage Rating	10 A
Current Rating	10 A
Voltage Rating	600V Max kV
Wattage	6000

Conductor Related

Conductor Size	#16 AWG
Conductor Type	Copper
Number Of Conductors	2

Certifications and Compliance

Nema Rating	Non-NEMA
-------------	----------

Product Assets

- [Engineering Drawing - RF1002PE001 AutoCAD Drawing](#)
- [Installation Manuals - WIRING_PD2039_INSTALLINST](#)
- [Literature - WIRING_WLFVM034](#)
- [Literature - Linkosity Wiring System](#)
- [Literature - Pulp & Paper Solutions](#)
- [Sales Drawings - WDK_RF1002PE001_DRAWING_PDF](#)
- [Warranty - Industrial & Commercial Products](#)



A proud member of the Hubbell Family.