




Wiring Device-Kellems

# Linkosity, Female Receptacle, 10A, 10P, 10'

By Hubbell Wiring Device-Kellems  
Catalog # [RF1010PE010](#)

Linkosity, Female Receptacle, 10A, 10P, 10'

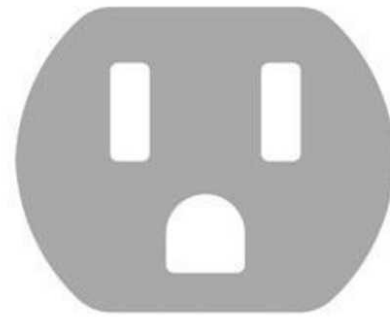

**Oh No!**  
IMAGE COMING SOON

## Application

Power and Control Integration

## General

Color	Gray
Construction	Fabricated
EU RoHS Indicator	Yes
Item Type	Female Receptacle
Material	Composite
Number Of Poles	10-Pole
OEM Brand Name	Hubbell Wiring Device-Kellems
UPC	783585505022

## Electrical Ratings

Amperage Rating	10 A
Current / Amperage Rating	10 A
Current Rating	10 A
Voltage Rating	600V Max kV
Wattage	6000

## Conductor Related

Conductor Size	#16 AWG
Conductor Type	Copper
Number Of Conductors	10

## Certifications and Compliance

Nema Rating	Non-NEMA
-------------	----------

## Logistics

Carton Quantity	50
-----------------	----

## Product Assets

- [Engineering Drawing - RF1010PE010 AutoCAD Drawing](#)
- [Installation Manuals - WIRING\\_PD2039\\_INSTALLINST](#)
- [Literature - WIRING\\_WLFVM034](#)
- [Literature - Linkosity Wiring System](#)
- [Literature - Pulp & Paper Solutions](#)
- [Sales Drawings - WDK\\_RF1010PE010\\_DRAWING\\_PDF](#)
- [Warranty - Industrial & Commercial Products](#)



A proud member of the Hubbell Family.