


## RCPT DUP, 15A 125V, B/S WIRE QCK-PLT, IV

By Hubbell Wiring Device-Kellems  
Catalog # RR15QI

RCPT DUP, 15A 125V, B/S WIRE QCK-PLT, IV

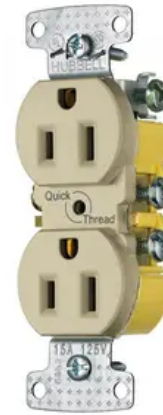

### Features

- Smooth indented face appearance
- Multiple-drive Slot/Phillips/Robertson head screws
- Tough thermoplastic ultrasonically welded cover and base

### Application

Residential Receptacles

### General

Catalog Number	RR15QI
Color	Ivory
EU RoHS Indicator	Contact Manufacturer
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	Traditional Duplex
Material	Thermoplastic
Material - Mounting Hardware	Screw Mounting
Number Of Poles	2-Pole
OEM Brand Name	Hubbell Wiring Device-Kellems
UPC	883778110719

### Dimensions

Display Size	Standard Sized Product
--------------	------------------------

### Electrical Ratings

Amperage Rating	15 A
Connectivity	Push and Side Wire
Current / Amperage Rating	15 A
Current Rating	15 A
Phase	Single Phase
Voltage Rating	125 VAC
Wattage	1875

### Conductor Related

Number Of Wires	3-Wire Grounding
Wire Size	#14 AWG to #12 AWG

### Certifications And Compliance

Nema Rating	5-15R
-------------	-------

### Logistics

Carton Quantity	10
-----------------	----

### Product Assets

[Catalogs - WDK Catalog Full 2024](#)  
[Engineering Drawing - RR15QI AutoCAD Drawing](#)  
[Sales Drawings - WDK\\_RR15Q\\_DRAWINGS\\_PDF](#)  
[Specifications - RR15QI](#)  
[Warranty - tradeSELECT™ and netSELECT®](#)