


**TradeSelect, Straight Blade Devices,
Receptacles, Residential Grade,
Duplex, 15A 125V, 2-Pole 3-Wire
Grounding, 5-15R, Self Grounding,
White**

By Hubbell Wiring Device-Kellems
Catalog # [RR15S](#)

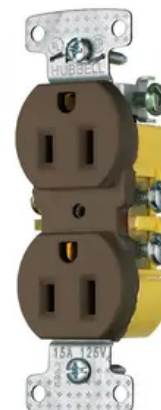

TradeSelect, Straight Blade Devices, Receptacles, Residential
Grade, Duplex, 15A 125V, 2-Pole 3-Wire Grounding, 5-15R, Self
Grounding, White

Features

- Smooth indented face appearance
- Multiple-drive Slot/Phillips/Robertson head screws
- Tough thermoplastic ultrasonically welded cover and base

Application

Residential Receptacles

Performance

- Environmental - Operating temperature - -20°C to 60°C
- Mechanical - Terminal - Terminal screws accepts up to #12 AWG, Push wire designed for #14 AWG solid copper wire only

General

Catalog Number	RR15S
Color	Brown
EU RoHS Indicator	Yes
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	Traditional Duplex
Material	Thermoplastic
Material - Mounting Hardware	Screw Mounting
Number Of Poles	2-Pole
OEM Brand Name	Hubbell Wiring Device-Kellems
Specifications	<ul style="list-style-type: none">Material - ThermoplasticNumber of Poles - 2 PoleProduct Type - ReceptacleReceptacle Type - Duplex
UPC	883778100055

Dimensions

Display Size

Standard Sized Product

Electrical Ratings

Amperage Rating	15 A
Connectivity	Push and Side Wire
Current / Amperage Rating	15 A
Current Rating	15 A
Phase	Single Phase
Voltage Rating	125 VAC
Voltage Rating Description	125 VAC
Wattage	1875

Conductor Related

Number Of Wires	3-Wire Grounding
Wire Size	#14 AWG to #12 AWG

Certifications And Compliance

Nema Rating 5-15R

Logistics

Carton Quantity 10

Product Assets

Catalogs - WDK Catalog Full 2024
Engineering Drawing - RR15S AutoCAD Drawing
Sales Drawings - WDK_RR15S_DRAWINGS_PDF
Specifications - RR15S
Warranty - tradeSELECT™ and netSELECT®
Video - Tradeselect Devices