




Snap-Fit, Keystone, 3.5 MM Stereo Jack, Screw Terminal, Black

By Hubbell Wiring Device-Kellems
Catalog # [SF35STBK](#)

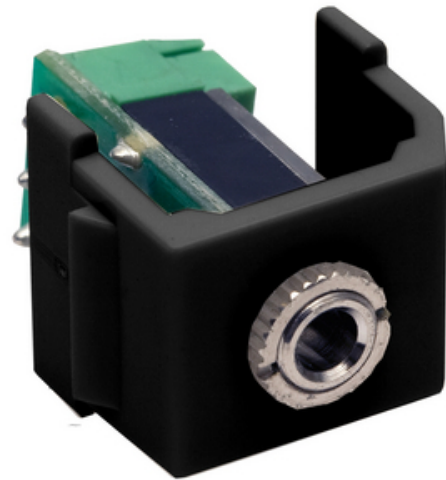

Snap-Fit, Keystone, 3.5 MM Stereo Jack, Screw Terminal, Black

Application

Snap-Fit 3.5mm Audio Jack

General

Contact	Beryllium Copper
EU RoHS Indicator	Yes
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	iSTATION AV Keystone Connections
Material - Mounting Hardware Style	Snap-On- Snap-Fit 3.5mm to Screw Terminal
Temperature Rating	Per TIA
Type	Stereo Jack
UPC	662620287874

Dimensions

Display Size	Standard Sized Product
--------------	------------------------

Electrical Ratings

Connectivity	Screw Terminals
Contact Resistance	100 Ohm
Withstand Voltage	1000V RMS, 1414V DC

Certifications and Compliance

Industry Standard(s)	UL Listed
----------------------	-----------

Logistics

Carton Quantity	25
-----------------	----

Product Assets

[Catalog Page - Wiring Z-8 Catalog page](#)
[Catalogs - Wiring Full Catalog](#)
[Literature - Hubbell SystemOne Recessed Fire-Rated Poke-Throughs: 4, 6, 8 and 10 inch](#)
[Literature - Hubbell SystemOne Recessed Fire-Rated Poke-Throughs](#)
[Warranty - Industrial & Commercial Products](#)

Related Products

[SF35STEI - Snap-Fit, Keystone, 3.5 MM Stereo Jack, Screw Terminal, Electric Ivory](#)
[SF14SJBK - Stereo Jack, Snap-Fit, 1/4", Keystone, Snap-Fit, Black](#)
[SF35SJAL - Stereo Jack, Snap-Fit, Keystone, 3.5 MM Stereo Jack, Solder Termination, Almond](#)
[SF35FFBK - Snap-Fit, Keystone, 3.5 MM Stereo Jack, Female to Female, Black](#)
[SF35STOW - Snap-Fit, Keystone, 3.5 MM Stereo Jack, Screw Terminal, Office White](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
WDK-SF35STBK-SPEC-EN | REV 5/2023