




## Connector, Snap-Fit, RCA to F-Coupler, Black

By Hubbell Wiring Device-Kellems  
Catalog # [SFRFGBK](#)

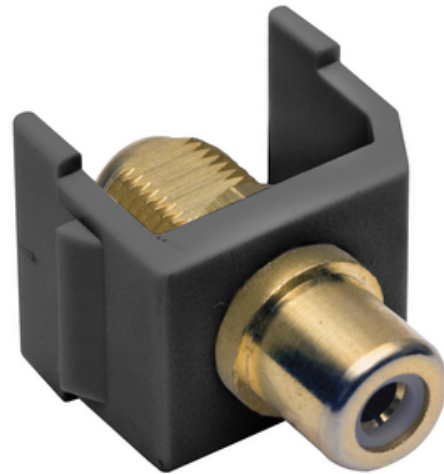

Connector, Snap-Fit, RCA to F-Coupler, Black

### Application

Snap-Fit RCA to F-Connector

### General

Contact	Beryllium Copper
EU RoHS Indicator	Yes
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	iSTATION RCA and F-Keystone Connectors
Material - Mounting Hardware Style	Snap-On- Snap-Fit RCA to F-Connector
Temperature Rating	Per TIA
Type	F-Type
UPC	662620854441

### Dimensions

Display Size Standard Sized Product

### Electrical Ratings

Connectivity	Female to Female
Contact Resistance	100 Ohm
Withstand Voltage	1000V RMS, 1414V DC

### Logistics

Carton Quantity 25

### Product Assets

[Catalog Page - Wiring\\_Catalog\\_Z6\\_CatPage](#)  
[Catalogs - Wiring Full Catalog](#)  
[Literature - Hubbell SystemOne Recessed Fire-Rated Poke-Throughs: 4, 6, 8 and 10 inch](#)  
[Literature - Connexion 2.0 Zone Distribution System](#)  
[Warranty - Industrial & Commercial Products](#)

### Related Products

[SFFGBK - Snap-Fit, Gold F-Coax Connector, Almond](#)  
[SFFBX - Snap-Fit, F-Coax Connector, Black](#)  
[SFGRFBK - Snap-Fit, Recessed F-Coax Connector, Black](#)  
[NSF70BK - Snap-In, F Coax, Nickel, Black](#)  
[SFRFGBK - Connector, Snap-Fit, RCA to F-Coupler, Black](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.  
WDK-SFRFGBK-SPEC-EN | REV 5/2023