




# Snap-Fit, Keystone, USB, A to B, Black

By Hubbell Wiring Device-Kellems  
Catalog # [SFUSBABB](#)

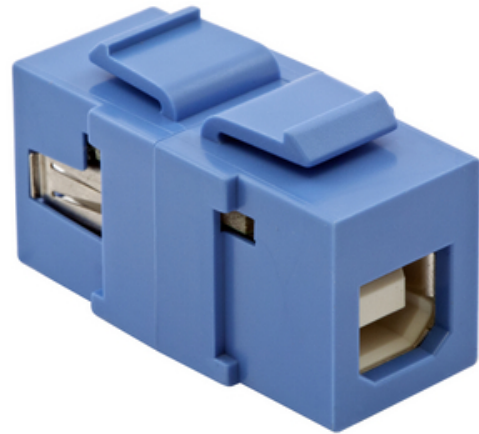

Snap-Fit, Keystone, USB, A to B, Black

## Application

Snap-Fit USB Jack

## General

Contact	Beryllium Copper
EU RoHS Indicator	Yes
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	iSTATION RCA and Data Keystone Connectors
Material - Mounting Hardware Style	Snap-On- Snap-Fit USB
Temperature Rating	Per TIA
Type	Data
UPC	662620287638

## Dimensions

Display Size	Standard Sized Product
--------------	------------------------

## Electrical Ratings

Connectivity	Plug-N-Play
Contact Resistance	100 Ohm
Withstand Voltage	1000V RMS, 1414V DC

## Certifications and Compliance

Industry Standard(s)	UL Listed
----------------------	-----------

## Logistics

Carton Quantity	25
-----------------	----

## Product Assets

[Catalog Page - Wiring Z-5 Catalog page](#)  
[Catalogs - Wiring Full Catalog](#)  
[Literature - Hubbell SystemOne Recessed Fire-Rated Poke-Throughs: 4, 6, 8 and 10 inch](#)  
[Literature - Hubbell SystemOne Recessed Fire-Rated Poke-Throughs](#)  
[Warranty - Industrial & Commercial Products](#)

## Related Products

[SFUSBAAB - Snap-Fit, Keystone, USB, A to A, Black](#)  
[SFUSBABW - Snap-Fit, Keystone, USB, A to B, White](#)  
[SFSC6 - Snap-Fit, Inline Coupler, Slim, Cat6, Shielded](#)  
[SFUSBAAOW - Snap-Fit, Keystone, USB, A to A, Office White](#)  
[SF5ECOY - Inline Coupler, Snap-Fit, Slim, X Over 10/100, Gray](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.  
WDK-SFUSBABB-SPEC-EN | REV 5/2023