




Snap-Fit, Keystone, USB, A to B, Office White

By Hubbell Wiring Device-Kellems
Catalog # [SFUSBABOW](#)

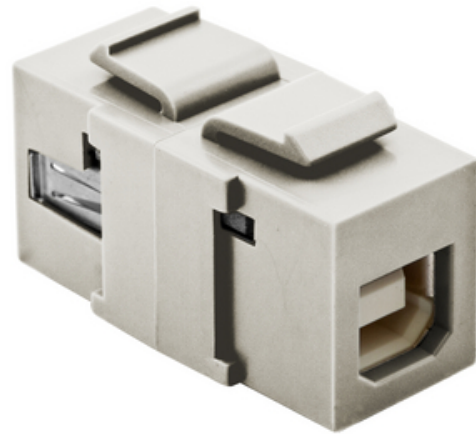

Snap-Fit, Keystone, USB, A to B, Office White

Application

Snap-Fit USB Jack

General

Contact	Beryllium Copper
EU RoHS Indicator	Yes
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	iSTATION RCA and Data Keystone Connectors
Material - Mounting Hardware Style	Snap-On- Snap-Fit USB
Temperature Rating	Per TIA
Type	Data
UPC	662620289168

Dimensions

Display Size	Standard Sized Product
--------------	------------------------

Electrical Ratings

Connectivity	Plug-N-Play
Contact Resistance	100 Ohm
Withstand Voltage	1000V RMS, 1414V DC

Certifications and Compliance

Industry Standard(s)	UL Listed
----------------------	-----------

Logistics

Carton Quantity	25
-----------------	----

Product Assets

[Catalog Page - Wiring Z-5 Catalog page](#)
[Catalogs - Wiring Full Catalog](#)
[Literature - Hubbell SystemOne Recessed Fire-Rated Poke-Throughs: 4, 6, 8 and 10 inch](#)
[Literature - Hubbell SystemOne Recessed Fire-Rated Poke-Throughs](#)
[Warranty - Industrial & Commercial Products](#)

Related Products

[SFUSBABW - Snap-Fit, Keystone, USB, A to B, White](#)
[SFUSBAA3BK - Keystone USB Jack, Snap-Fit, V3.0, A to A, Black](#)
[SFC6BK - Snap-Fit, Inline Coupler, Cat6, Slim, Black](#)
[SFC5EBK - Snap-Fit, Inline Coupler, Cat5e, Slim, Black](#)
[SFUSBAAB - Snap-Fit, Keystone, USB, A to A, Black](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
WDK-SFUSBABOW-SPEC-EN | REV 5/2023