




XLR Connector, Screw Terminal, Panel Mount, 3-Pin, 10 Pack

By Hubbell Wiring Device-Kellems
Catalog # [XLRST10](#)

XLR Connector, Screw Terminal, Panel Mount, 3-Pin, 10 Pack

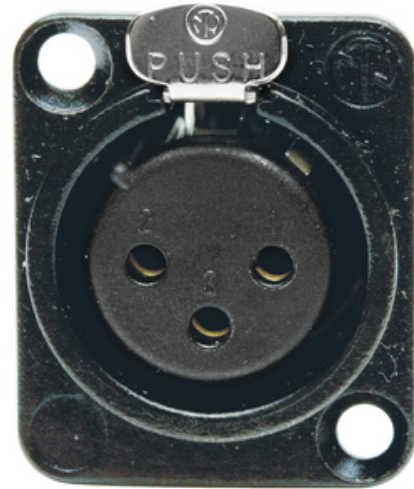

Application

D-Style XLR 3-Pole Locking Connection

General

Contact	Beryllium Copper
EU RoHS Indicator	Yes
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	iSTATION Pro Audio D-Style Connections
Material - Mounting Hardware	Snap-On- Snap-Fit
Temperature Rating	Per TIA
Type	XLR
UPC	662620285405

Dimensions

Display Size	Standard Sized Product
--------------	------------------------

Electrical Ratings

Connectivity	Screw Terminals
Contact Resistance	100 Ohm
Withstand Voltage	1000V RMS, 1414V DC

Logistics

Carton Quantity	5
-----------------	---

Product Assets

[Catalog Page - Wiring Z-14 Catalog page](#)
[Catalogs - Wiring Full Catalog](#)
[Warranty - Industrial & Commercial Products](#)

Related Products

[SC10 - Connectors, Speakon Jack, Solder Type, Panel Mount, 10 Pack](#)
[14S10 - 1/4" Audio Jack, Solder Type, Panel Mount, 10 Pack](#)
[XLR10 - XLR Connector, Solder Type, Panel Mount, 3-Pin, 10 Pack](#)
[IMAVB15W - iStation Module, Audio/Video, Unloaded, 1.5-Unit, White, 10 Pack](#)
[IMAVB15OW - iStation Module, Audio/Video, Unloaded, 1.5-Unit, Office White, 10 Pack](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
WDK-XLRST10-SPEC-EN | REV 5/2023