


1-Gang, Rectangular, Galvanized
Stamped Steel Box, Deep, Fully
Adjustable, Single Service,
Aluminum Top

By Hubbell Wiring Device-Kellems
Catalog # [BA2431](#)

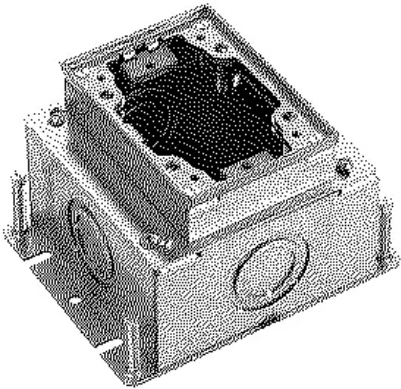

Flush Concrete Floor Box Series, 1-Gang, Rectangular,
Galvanized Stamped Steel Box, Deep, Fully Adjustable, Single
Service, Aluminum Top

Features

- Stamped steel construction
- Concentric knockouts permit various conduit sizes
- Economical and light weight for above-grade applications

General

Application - For Use On	Concrete
Catalog Number	BA2431
Construction	Stamped
EU RoHS Indicator	No
Knockouts	4)3/4"- 1 1/4"
Material	Galvanized Stamped Steel
Mounting Method	Cast Into Concrete
Number of Gang(s)	1-Gang
Series	Flush Rectangular - B24 Series
Size	1-Gang
Specifications	• Collar Material - Aluminum • Cubic Capacity - 60.0 cu. in. (983.2 cm3) • Min. Depth of Pour - 3.75" (95.3) • Size - 1-Gang
UPC	783585104218

Dimensions

Dimensions	4.81 in x 6 in x 3.72 in
------------	--------------------------

Height	3.72 in
Length	4.81 in
Width	6 in

Conductor Related

Cable Entry	From Top
-------------	----------

Certifications And Compliance

Industry Standard(s)	• UL/CSA • UL514
Standards - RoHS Compliance Status	CM

Logistics

Carton Quantity	4
-----------------	---

Product Assets

[Catalogs - WDK Catalog Full 2024](#)
[Engineering Drawing - BA2431 AutoCAD Drawing](#)
[Installation Manuals - WIRING_PD1437_INSTALLINST](#)
[Sales Drawings - WDK_BA2431_DRAWING_PDF](#)
[Specifications - Wiring BA2431 Specification Sheet](#)
[Specifications - BA2431 Specification Sheet](#)
[Specifications - BA2431 Specification Sheet French](#)
[Warranty - Industrial & Commercial Products](#)