


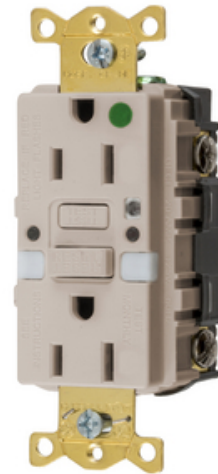

GFRST82LANL

By Hubbell Wiring Device-Kellems
Catalog # [GFRST82LANL](#)

Straight Blade Devices, Receptacle, GFCI, Commercial Hospital Grade, Self Test, 15A 125V, 2-Pole 3-Wire Grounding, 5-15R, Light Almond, With Night Light.



Features

- Green power indicator and red trip indicator
- Patented AUTOGUARD® self test technology
- Triple wipe construction
- Includes light sensor controls for automatic on and off, custom dual lens for optimum light output

General

Color	<ul style="list-style-type: none">• Light Almond• Amande pâle
EU RoHS Indicator	Contact Manufacturer
Series	Hospital Grade
Style	Nightlight
Type	<ul style="list-style-type: none">• Standard• Standard
UPC	783585485959

Electrical Ratings

Current / Amperage Rating	15 A
Voltage Rating Description	125 V

Certifications and Compliance

Industry Standard(s)	Meets All NEC® Requirements
Nema Rating	5-15R

Logistics

Carton Quantity	10
-----------------	----

Product Assets

[Catalog Page - WDK L-15 Catalog Page](#)
[Catalog Page - WDK K-6 Catalog Page](#)
[Catalogs - WDK Catalog Full 2023](#)
[Engineering Drawing - GFRST82LANL AutoCAD Drawing](#)
[Installation Manuals - WIRING_PD2082_INSTALLINST](#)
[Literature - Duct Products Guide](#)
[Literature - Hubbell-PRO Hospital Grade TR Receptacles](#)
[Literature - AUTOGUARD® Self Test Ground Fault Receptacles](#)
[Sales Drawings - WDK_GFRST82LANL_DRAWINGS_PDF](#)
[Warranty - Industrial & Commercial Products](#)
[Video - Autoguard GFCI Receptacles](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.
WDK_CA-GFRST82LANL-SPEC-EN | REV 1/2024