




Wiring Device-Kellems

GFRST82SNAPAL

By Hubbell Wiring Device-Kellems
Catalog # [GFRST82SNAPAL](#)

SNAP-Connect Straight Blade GFCI Hospital Grade Receptacle, 15A 125V, 2-Pole 3-Wire Grounding, 5-15R.

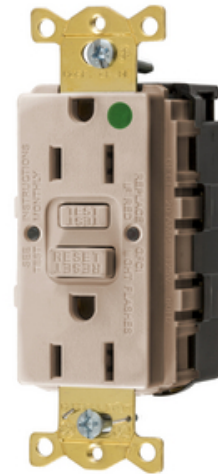

Features

- Audible SNAP, indicates solid connection
- Patented shutter design for tamper-resistant
- Compliant with NEC® 406.12 and NEC® 517-18(c)
- Patented AUTOGUARD® self test technology
- Triple wipe construction

General

Color	<ul style="list-style-type: none"> • Almond • Amande
EU RoHS Indicator	Contact Manufacturer
Horsepower - Maximum	0.5
Item Type	Self test GFCI receptacle
Material	Nylon
Series	Hospital Grade
Style	Standard
Type	<ul style="list-style-type: none"> • Standard • Standard
UPC	783585486222

Dimensions

Dimensions	3.28 in x 1.77 in x 1.47 in
Height	1.47 in
Length	3.28 in
Width	1.77 in

Electrical Ratings

Current / Amperage Rating	15 A
Phase	Single Phase
Voltage Rating	125 V
Voltage Rating Description	125 V
Wattage	1875 W

Conductor Related

Wire Size	#12 AWG
-----------	---------

Certifications and Compliance

Industry Standard(s)	Meets All NEC® Requirements
Nema Rating	5-15R

Logistics

Carton Quantity	10
-----------------	----

Product Assets

- [Catalogs - WDK Catalog Full 2023](#)
- [Engineering Drawing - GFRST82SNAPAL AutoCAD Drawing](#)
- [Installation Manuals - WIRING_PD2484_INSTALLINST](#)
- [Literature - Duct Products Guide](#)
- [Literature - AUTOGUARD® Self Test Ground Fault Receptacles](#)
- [Sales Drawings - WDK_GFRST82SNAP_DRAWING_PDF](#)

Related Products

[SNAPIRA](#)



A proud member of the Hubbell Family.