


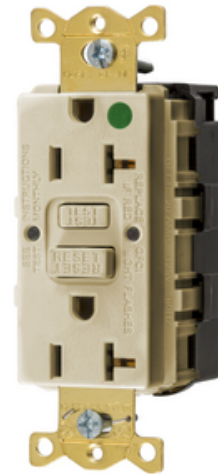

GFRST83SNAPI

By Hubbell Wiring Device-Kellems
Catalog # [GFRST83SNAPI](#)

SNAP-Connect Straight Blade GFCI Receptacle, Commercial Hospital Grade, Self Test, 20A 125V, 2-Pole 3-Wire Grounding, 5-20R.



Features

- Audible SNAP, indicates solid connection
- Patented shutter design for tamper-resistant
- Compliant with NEC® 406.12 and NEC® 517-18(c)
- Patented AUTOGUARD® self test technology
- Triple wipe construction

Application

Commercial Hospital Grade

General

Color	<ul style="list-style-type: none">• Ivory• Ivoire
EU RoHS Indicator	Contact Manufacturer
Horsepower - Maximum	1
Item Type	Self test GFCI receptacle
Material	Nylon
Series	Hospital Grade
Style	Standard
Type	<ul style="list-style-type: none">• Standard• Standard
UPC	783585486338

Dimensions

Dimensions	3.28 in x 1.77 in x 1.47 in
Height	1.47 in
Length	3.28 in
Width	1.77 in

Electrical Ratings

Amperage Rating	20 A
Current / Amperage Rating	20 A
Current Rating	20 A
Phase	Single Phase
Voltage Rating	125 V
Voltage Rating Description	125 V
Wattage	1875 W

Conductor Related

Wire Size	#12 AWG
-----------	---------

Certifications and Compliance

Industry Standard(s)	Meets All NEC® Requirements
Nema Rating	5-20R

Logistics

Carton Quantity	10
-----------------	----

Product Assets

[Catalog Page - WDK L-5 Catalog Page](#)
[Catalog Page - WDK L-15 Catalog Page](#)
[Catalog Page - WDK A-17 Catalog Page](#)
[Catalogs - WDK Catalog Full 2023](#)
[Engineering Drawing - GFRST83SNAPI AutoCAD Drawing](#)
[Installation Manuals - WIRING_PD2484_INSTALLINST](#)
[Literature - Duct Products Guide](#)
[Literature - Healthcare Application Guide](#)
[Literature - AUTOGUARD® Self Test Ground Fault Receptacles](#)
[Literature - SNAPConnect® Devices](#)
[Sales Drawings - WDK_GFRST83SNAP_DRAWING_PDF](#)
[Warranty - Industrial & Commercial Products](#)
[Video - Autoguard GFCI Receptacles](#)
[Video - SNAPConnect Devices](#)

Related Products

[SNAPIRA](#)





A proud member of the Hubbell Family.

WDK_CA-GFRST83SNAPI-SPEC-EN | REV 1/2024