




Straight Blade Devices, Receptacles, 4- Plex, Hospital Grade, 2-Pole 3-Wire Grounding, 20A 125V, 5-20R, Red, Single Pack

By Hubbell Wiring Device-Kellems
Catalog # [HBL420HR](#)

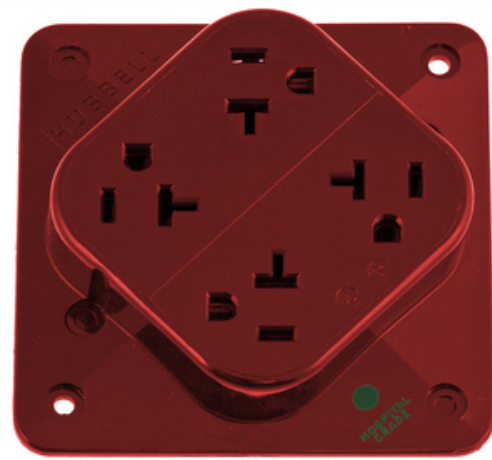

Straight Blade Receptacle, 4- Plex, Hospital Grade, 2-Pole 3-Wire Grounding, 20A 125V, 5-20R, Red.

Features

- Anchor hole and loop feature secures solid wire for fast, easy terminations
- Triple wipe contacts
- Easily accessible break-off tabs for split wiring
- Three conductors energize all four outlets

Application

4-Plex Hospital Grade

General

| | |
|------------------------------|--|
| Color | <ul style="list-style-type: none"> • Red • Rouge |
| Environmental Conditions | Indoor Dry Unless Protected By Additional Means |
| Horsepower - Maximum | 1 |
| Item Type | 4-PLEX |
| Material | Polycarbonate |
| Material - Mounting Hardware | Screw Mounting |
| Number Of Poles | 2-Pole |
| Operating Temperature | Maximum continuous 75°C and minimum -40°C without Impact |
| Performance | <ul style="list-style-type: none"> • Electrical - Current Interrupting - Capable of withstanding a fault level of 1000A, per UL498 • Electrical - Dielectric Voltage - Withstands 2,000V minimum • Environmental - Flammability - UL 94V-2 • Environmental - Operating Temperatures - Maximum continuous 75°C, minimum -40°C (w/o impact) • Mechanical - Product Identification - Ratings are a permanent part of the device • Mechanical - Terminal Accommodation - #12 AWG copper stranded or solid conductor only |

Dimensions

| | |
|--------------|---------------------------|
| Dimensions | 4.3 in x 4.3 in x 0.92 in |
| Display Size | Standard Sized Product |
| Height | 0.92 in |
| Length | 4.3 in |
| Weight | 0.4 lb |
| Width | 4.3 in |

Electrical Ratings

| | |
|----------------------------|----------------------------|
| Amperage Rating | 20 A |
| Connectivity | Back Wired Screw Terminals |
| Current / Amperage Rating | 20 A |
| Current Rating | 20 A |
| Dielectric Strength | Withstands 2,000V minimum |
| Phase | Single Phase |
| Voltage Rating | 125 VAC |
| Voltage Rating Description | 125 V |
| Wattage | 2500 W |

Conductor Related

| | |
|-----------------|---------|
| Number Of Wires | 3-Wire |
| Wire Size | #12 AWG |

Certifications and Compliance

| | |
|----------------------|---|
| Industry Standard(s) | <ul style="list-style-type: none"> • Certified to CSA, C22.2, No. 42 File 285 • NEMA® WD-6 Compliant • UL Listed to UL498 File No. E2186 |
| Nema Rating | 5-20R |

Logistics

| | |
|-----------------|---|
| Carton Quantity | 5 |
|-----------------|---|

Product Assets

[Catalog Page - WDK A-32](#) [Catalog Page](#)
[Catalog Page - WDK L-10](#) [Catalog Page](#)
[Catalogs - WDK Catalog Full 2023](#)
[Engineering Drawing - HBL420HR AutoCAD Drawing](#)
[Installation Manuals - WIRING_D5510101_INSTALLINST](#)
[Literature - Duct Products Guide](#)
[Sales Drawings - WDK_HBL420_DRAWING_PDF](#)
[Warranty - Industrial & Commercial Products](#)

- solid conductor only
- Mechanical - Terminal Identification - Terminals identified in accordance with UL 498 and CSA

Series

Hospital Grade

Style

Smooth Face

Type

- 4-PLEX Receptacle
- 4-PLEX Receptacle

UPC

783585015781



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.
WDK_CA-HBL420HR-SPEC-EN | REV 1/2024