




# Straight Blade Devices, Male Plug, Insulgrip Heavy Duty, Industrial/Commercial Grade, Straight, 2-Pole 3- Wire Grounding, 15A 250V, 6-15P and White

By Hubbell Wiring Device-Kellems  
Catalog # [HBL5666C](#)

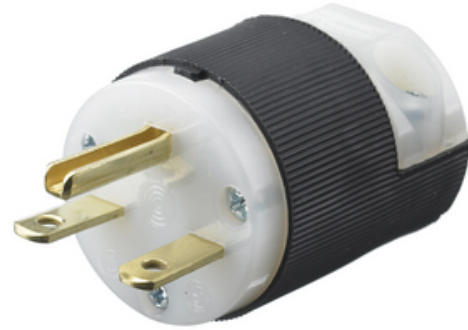

Insulgrip® Straight Blade Male Plug 15A, 2-Pole, 3-Wire Grounding, 250V, 6-15P/White.

## Features

- Ribbed nylon housing is impact and chemical resistant
- VARI-SIZE adjustable cord clamp
- Fast lead assembly screws
- Beveled housing prevents snagging

## General

Color	<ul style="list-style-type: none"> <li>• Noir, blanc</li> <li>• Noir, blanc</li> </ul>
Environmental Conditions	Ribbed Nylon Housing Is Impact and Chemical Resistant
Horsepower - Maximum	1.5
Item Type	Insulgrip Plug
Number Of Poles	2-Pole
Operating Temperature	Maximum continuous 75°C and minimum -40°C without Impact
Performance	<ul style="list-style-type: none"> <li>• Electrical - Current Interrupting - Certified for current interrupting at full rated current</li> <li>• Electrical - Dielectric Voltage - Withstands 2,000V minimum</li> <li>• Environmental - Flammability - UL 94 HB or better</li> <li>• Environmental - IP Suitability - IP20</li> <li>• Environmental - Operating Temperatures - Maximum continuous 75°C minimum -40°C (w/o impact)</li> <li>• Mechanical - Terminal Accommodation - #18-10 AWG. Standed copper wire only</li> <li>• Mechanical - Terminal Identification - Terminals identified in accordance with UL 498 and CSA</li> </ul>

## Dimensions

Dimensions	1.97 in x 1.53 in x 1.53 in
Height	1.53 in
Length	1.97 in
Weight	0.15 lb
Width	1.53 in

## Electrical Ratings

Amperage Rating	15 A
Current / Amperage Rating	15 A
Current Rating	15 A
Dielectric Strength	Withstands 2,000V minimum
Voltage Rating	250 V
Voltage Rating Description	250 V
Wattage	3750 W

## Conductor Related

Number Of Wires	3-Wire
Wire Size	#18 AWG to #10 AWG

## Certifications and Compliance

Industry Standard(s)	<ul style="list-style-type: none"> <li>• CSA Certified to C22.2 No. 42 File 280</li> <li>• NEMA® WD-6 Compliant</li> <li>• UL Listed to UL498 File E1706</li> </ul>
Nema Rating	6-15P
Standards - RoHS Compliance Status	CM

## Logistics

Carton Quantity	10
-----------------	----

## Product Assets

- [Catalog Page - WDK A-40 Catalog Page](#)
- [Catalogs - WDK Catalog Full 2023](#)
- [Engineering Drawing - HBL5666C AutoCAD Drawing](#)
- [Installation Manuals - WIRING\\_PD2437\\_INSTALLINST](#)
- [Literature - Industrial Solutions](#)
- [Sales Drawings - WDK\\_HBL5666C\\_DRAWING\\_PDF](#)
- [Warranty - Industrial & Commercial Products](#)
- [Video - Insulgrip Twist-Lock and Straight Blade Devices](#)

Series  
Style  
Type  
  
UPC

Insulgrip®  
Standard  
• Plug  
• Plugs  
  
783585175607



**A proud member of the Hubbell Family.**

©2024 Hubbell Incorporated. All rights reserved.  
WDK\_CA-HBL5666C-SPEC-EN | REV 1/2024