




# Straight Blade Devices, Female Connector Body, Valise Series, Industrial/Commercial Grade, Straight, 2-Pole 3- Wire Grounding, 15A 250V, 6-15R

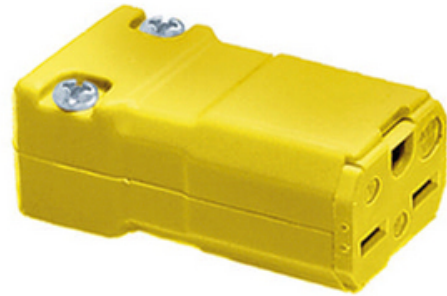

By Hubbell Wiring Device-Kellems  
Catalog # [HBL5669VY](#)

Valise® Straight Blade Female Connector Body 15A, Straight, 2-Pole 3-Wire Grounding, 250V, 6-15R/White.

## Features

- Hinged one piece body design for easy assembly
- Powerful, offsetting cord grips clamp on individual conductors
- Assembly screws are captive and will not fall out while wiring

## Application

Industrial/Commercial

## General

Cord Range	0.220"-0.660" (5.6-16.8)
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Insulation	Insulated Body
Item Type	Valise
Material	Nylon
Material - Mounting Hardware	Cord Mounted
Number Of Poles	2-Pole
Operating Temperature	Maximum continuous 75°C and minimum -40°C without impact
Performance	<ul style="list-style-type: none"> <li>• Electrical - Current Interrupting - Certified for current interrupting at full rated current</li> <li>• Electrical - Dielectric Voltage - Withstands 2,000V minimum</li> <li>• Environmental - Flammability - UL 94 HB or better</li> <li>• Environmental - IP Suitability - IP20</li> <li>• Environmental - Operating Temperatures - Maximum continuous 75°C minimum -40°C (w/o impact)</li> <li>• Mechanical - Product Identification - Ratings are a permanent part of the device</li> <li>• Mechanical - Terminal</li> </ul>

## Dimensions

Dimensions	2.38 in x 1.25 in x 0.88 in
Display Size	Standard
Height	0.88 in
Length	2.38 in
Weight	0.15 lb
Width	1.25 in

## Electrical Ratings

Amperage Rating	15 A
Connectivity	Screw Terminals
Current / Amperage Rating	15 A
Current Rating	15 A
Dielectric Strength	Withstands 2,000V minimum
Voltage Rating	250 V
Voltage Rating Description	250 V
Wattage	3750 W

## Conductor Related

Conductor Range	#14 AWG to #12 AWG
Number Of Conductors	3-Wire Grounding
Number Of Wires	3-Wire
Wire Size	#18 AWG to #12 AWG

## Certifications and Compliance

Industry Standard(s)	<ul style="list-style-type: none"> <li>• CSA Certified to C22.2 No. 42 File 280C</li> <li>• NEMA® WD-6 Compliant</li> <li>• UL Listed to UL498 File E1706</li> </ul>
Nema Rating	6-15R
Standards - RoHS Compliance Status	CM

## Logistics

Carton Quantity	10
-----------------	----

## Product Assets

[Catalog Page - WDK A-40 Catalog Page](#)  
[Catalogs - WDK Catalog Full 2023](#)  
[Installation Manuals - WIRING\\_PD1237\\_INSTALLINST](#)

Mechanical - Terminal  
Accommodation - #18-#12  
AWG stranded copper wire  
only

[Literature - WIRING\\_WLFVM034](#)  
[Literature - Pulp & Paper Solutions](#)  
[Warranty - Industrial & Commercial Products](#)

- Mechanical - Terminal  
Identification - Terminals  
identified in accordance  
with UL 498 and CSA

Series	Valise®
Style	Standard
Temperature Rating	Max Continuous- 75 Degrees C, Minimum- -40 Without Impact
Type	<ul style="list-style-type: none"><li>• Connector Body</li><li>• Connector Body</li></ul>
UPC	783585013213



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.  
WDK\_CA-HBL5669VY-SPEC-EN | REV 1/2024