




Wiring Device-Kellems

# Straight Blade Devices, Male Plug, Insulgrip, Hospital Grade, Straight, 2-Pole 3-Wire Grounding, 15A 125V, 5-15P, Black and White, Single Pack

By Hubbell Wiring Device-Kellems  
Catalog # [HBL8215C](#)

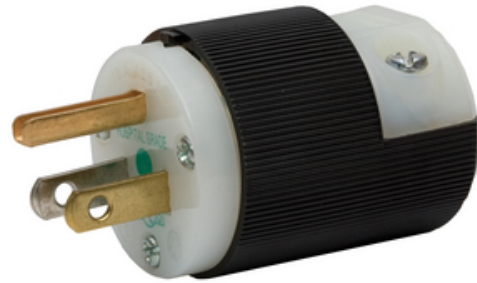

Insulgrip® Straight Blade Hospital Grade Male Plug 15A, 2-Pole, 3-Wire Grounding, 125V, 5-15P/White Nylon.

## Features

- Beveled housing prevents snagging
- Powerful, offsetting cord grips clamp on individual conductors

## Application

Hospital Grade

## General

Color	<ul style="list-style-type: none"> <li>• Black and White</li> <li>• Noir, blanc</li> </ul>
Cord Range	0.230"-0.720" (5.8-18.3)
Horsepower - Maximum	0.5
Item Type	Insulgrip Plug
Material	Nylon
Number Of Poles	2-Pole
Operating Temperature	Maximum continuous 75°C and minimum -40°C without Impact
Performance	<ul style="list-style-type: none"> <li>• Electrical - Current Interrupting - Certified for current interrupting at full rated current</li> <li>• Electrical - Dielectric Voltage - Withstands 2000V AC minimum</li> <li>• Environmental - Flammability - UL 94 HB or better</li> <li>• Environmental - IP Suitability - IP20</li> <li>• Environmental - Operating Temperatures - Maximum continuous 75°C, minimum -40°C (w/o impact)</li> <li>• Mechanical - Product Identification - Ratings are a permanent part of the device</li> <li>• Mechanical - Terminal Accommodation - #18-10 AWG</li> <li>• Mechanical - Terminal Identification - Terminals</li> </ul>

## Dimensions

Dimensions	1.97 in x 1.53 in x 1.53 in
Height	1.53 in
Length	1.97 in
Weight	0.15 lb
Width	1.53 in

## Electrical Ratings

Amperage Rating	15 A
Current / Amperage Rating	15 A
Current Rating	15 A
Dielectric Strength	Withstands 2,000V minimum
Voltage Rating	125 V
Voltage Rating Description	125 V

## Conductor Related

Number Of Wires	3-Wire
Wire Size	#18 AWG to #10 AWG

## Certifications and Compliance

Industry Standard(s)	<ul style="list-style-type: none"> <li>• Certified to CSA, C22.2, No. 42 File 285</li> <li>• Fed. Spec. W-C-596</li> <li>• UL Listed to UL498 File No. E2186</li> </ul>
----------------------	---

Nema Rating 5-15P

Standards - RoHS Compliance CM Status

## Logistics

Carton Quantity 10

## Product Assets

- [Catalog Page - WDK L-11 Catalog Page](#)
- [Catalog Page - WDK A-36 Catalog Page](#)
- [Catalogs - WDK Catalog Full 2023](#)
- [Engineering Drawing - HBL8215C AutoCAD Drawing](#)
- [Installation Manuals - WIRING\\_PD2437\\_INSTALLINST](#)
- [Installation Manuals - WIRING\\_PD1214\\_INSTALLINST](#)
- [Literature - Duct Products Guide](#)
- [Literature - Healthcare Product Solutions](#)
- [Literature - Education Application Guide](#)
- [Literature - Emergency Preparedness for Healthcare](#)
- [Sales Drawings - WDK\\_HBL8215C\\_DRAWING\\_PDF](#)

identified in accordance  
with UL 498 and CSA

[Warranty - Industrial & Commercial Products](#)  
[Video - Insulgrip Twist-Lock and Straight Blade Devices](#)

Series	Hospital Grade
Style	Insulgrip
Type	<ul style="list-style-type: none"><li>• Plug</li><li>• Plug</li></ul>
UPC	783585179209



**A proud member of the Hubbell Family.**

©2024 Hubbell Incorporated. All rights reserved.  
WDK\_CA-HBL8215C-SPEC-EN | REV 1/2024