


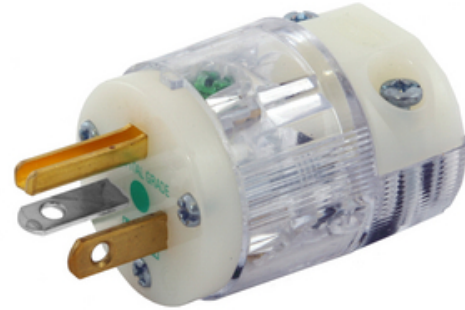

Straight Blade Devices, Male Plug, Insulgrip, Hospital Grade, Straight, 2-Pole 3-Wire Grounding, 20A 125V, 5-20P, Clear, Single Pack

By Hubbell Wiring Device-Kellems
Catalog # [HBL8315CT](#)



Insulgrip® Straight Blade Hospital Grade Male Plug 20A, 2-Pole, 3-Wire Grounding, 125V, 5-20P, Transparent.

Features

- Beveled housing prevents snagging
- Powerful, offsetting cord grips clamp on individual conductors

Application

Hospital Grade

General

Color	<ul style="list-style-type: none"> • Transparent • Transparent
Cord Range	0.230"-0.720" (5.8-18.3)
Horsepower - Maximum	1
Item Type	Insulgrip Plug
Number Of Poles	2-Pole
Operating Temperature	Maximum continuous 75°C and minimum -40°C without Impact

Performance	<ul style="list-style-type: none"> • Electrical - Current Interrupting - Certified for current interrupting at full rated current • Electrical - Dielectric Voltage - Withstands 2000V AC minimum • Environmental - Flammability - UL 94 HB or better • Environmental - IP Suitability - IP20 • Environmental - Operating Temperatures - Maximum continuous 75°C, minimum -40°C (w/o impact) • Mechanical - Product Identification - Ratings are a permanent part of the device • Mechanical - Terminal Accommodation - #18-10 AWG • Mechanical - Terminal Identification - Terminals identified in accordance
-------------	----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------

Dimensions

Dimensions	1.97 in x 1.53 in x 1.53 in
Height	1.53 in
Length	1.97 in
Weight	0.15 lb
Width	1.53 in

Electrical Ratings

Amperage Rating	20 A
Current / Amperage Rating	20 A
Current Rating	20 A
Dielectric Strength	Withstands 2,000V minimum
Voltage Rating	125 V
Voltage Rating Description	125 V

Conductor Related

Number Of Wires	3-Wire
Wire Size	#18 AWG to #10 AWG

Certifications and Compliance

Industry Standard(s)	<ul style="list-style-type: none"> • Certified to CSA, C22.2, No. 42 File 285 • Fed. Spec. W-C-596 • UL Listed to UL498 File No. E2186
----------------------	-------------------------------------------------------------------------------------------------------------------------------------------------------------------------

Nema Rating	5-20P
Standards - RoHS Compliance Status	CM

Logistics

Carton Quantity	10
-----------------	----

Product Assets

- [Catalog Page - WDK L-11 Catalog Page](#)
- [Catalog Page - WDK A-36 Catalog Page](#)
- [Catalogs - WDK Catalog Full 2023](#)
- [Engineering Drawing - HBL8315CT AutoCAD Drawing](#)
- [Installation Manuals - WIRING_PD2437_INSTALLINST](#)
- [Installation Manuals - WIRING_PD1214_INSTALLINST](#)
- [Literature - Duct Products Guide](#)
- [Literature - Healthcare Product Solutions](#)
- [Literature - Healthcare Application Guide](#)
- [Literature - Education Application Guide](#)
- [Literature - Emergency Preparedness for Healthcare](#)

with UL 498 and CSA

[Sales Drawings - WDK_HBL8315CT_DRAWING_PDF](#)
[Warranty - Industrial & Commercial Products](#)
[Video - Insulgrip Twist-Lock and Straight Blade Devices](#)

Series
Style
Type

Hospital Grade
Insulgrip
• Plug
• Plug

UPC

783585180052



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.
WDK_CA-HBL8315CT-SPEC-EN | REV 1/2024