


Cable Trak Separators, for HCT25 Series track

By Hubbell Wiring Device-Kellems
Catalog # [HCTSP25PK12](#)

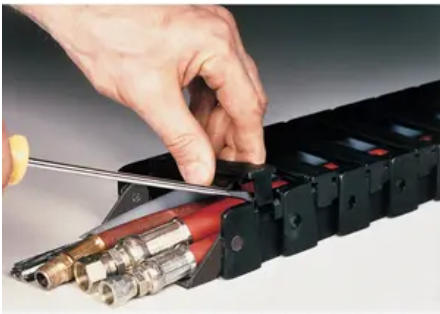

Cable Trak Separators, for HCT25 Series Track

Features

- for HCT25 Series track

Application

Cable and Hose Carrier

Performance

- Environmental - Maximum Operating Speed - 600 FPM (feet per minute), 180 MPM (meters per minute).
- Environmental - Operating Temperature - Continuous +20°F to +100°F (-7°C to 38°C)
- Intermittent* -40°F to +220°F (-40°C to 104°C).

General

Catalog Number	HCTSP25PK12
EU RoHS Indicator	No
Item Type	CableTrak Separator- 25mm
Material	Metallic
Specifications	• Applications - Machine tool, robotic automation, material handling • Material - Fiberglass reinforced nylon

UPC 783585022116

Dimensions

Display Size Standard Sized

Electrical Ratings

Connectivity Snap Together Sections

Logistics

Carton Quantity 10

Product Assets

- [Brochures - POWERTRAK® GRP Non-Metallic Cable/Hose Carrier](#)
- [Catalog Page - WDK I-11 Catalog Page](#)
- [Catalogs - WDK Catalog Full 2024](#)
- [Installation Manuals - WIRING_PD1593_INSTALLINST](#)
- [Sales Drawings - WDK_HCTSP25PK12_DRAWING_PDF](#)
- [Specifications - HCTSP25PK12 Specification Sheet French](#)
- [Specifications - HCTSP25PK12 Specification Sheet](#)
- [Specifications - Wiring HCTSP25PK12 Spec Sheet](#)
- [Warranty - Industrial & Commercial Products](#)