


# Non-Metallic Raceway, Super BaseTrak, Base, Cover, 10'

By Hubbell Wiring Device-Kellems  
Catalog # [PS3BC10](#)

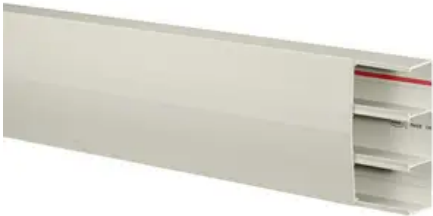

Non-Metallic Raceway, Super BaseTrak, Base, Cover, 10'

### Features

- UL Listed and CSA Certified to 600 volts
- Single and two channel latching raceways are dual-rated for both power and data applications, reducing inventory requirements

### Performance

- Environmental - Flame Rating - UL94V-0
- Environmental - Temperature Range - -25.6° to 158° F

### General

Catalog Number	PS3BC10
Construction	Extruded Plastic
Cover Type	Removable
EU RoHS Indicator	Yes
Enclosure Type	NEMA 1 Rating
Item Type	PS3, 3-Channel Super BaseTrak
Knockouts	None
Material	Thermoplastic
Series	PS3
Specifications	<ul style="list-style-type: none"><li>• Crush Resistance - 300 lbs.</li><li>• Impact Resistance - 5 ft. lbs.</li><li>• Length - 10 ft. (3m)</li></ul>

Style	• Material - UV Stabilized PVC
UPC	Three Channel 783585090047

### Dimensions

Length	10 ft
Width	6.7 in

### Certifications And Compliance

Industry Standard(s)	<ul style="list-style-type: none"><li>• CSA Standard C22.2 no. 62</li><li>• E118895 / E119190</li><li>• UL Standard UL 5A</li></ul>
Non Hazardous Location	Non Hazardous

### Product Assets

- [Catalog Page - WDK S-61 Catalog Page](#)
- [Catalogs - WDK Catalog Full 2024](#)
- [Engineering Drawing - PS3BC10 AutoCAD Drawing](#)
- [Installation Manuals - WIRING\\_PD1608\\_INSTALLINST](#)
- [Sales Drawings - WDK\\_PS3BC10\\_DRAWING\\_PDF](#)
- [Specifications - Wiring PS3BC10 Specification Sheet](#)
- [Specifications - PS3BC10 Specification Sheet](#)
- [Specifications - PS3BC10 Specification Sheet French](#)
- [Warranty - Industrial & Commercial Products](#)