

Fluorescent Lamp Holders,
Compact Type, 18-55 Watt 2G11,
Horizontal Mount, Snap-In

By Hubbell Wiring Device-Kellems
Catalog # [RL42G11HSM](#)

Fluorescent Lamp Holders, Compact Type, 18-55 Watt 2G11,
Horizontal Mount, Snap-In

Features

- Compact Type
- 18-55 Watt 2G11
- Horizontal Mount
- Snap-In

Application


Compact Fluorescent

Performance

- Electrical - Rating - 26-32W lamp type, 75W, 600V
- Mechanical - Terminal Accommodation - Push-in wire terminals for #18 AWG solid or twist and tin stripped 7/16 inch wire

General

Catalog Number	RL42G11HSM
EU RoHS Indicator	No
Item Type	Fluorescent Lampholders
Lamp Size	2-G11 Base 4) Pin
Material	Composite
Material - Mounting Hardware	Horizontal Screw Down
Series	Lampholders
Specifications	<ul style="list-style-type: none">• Lamp Type - 18-55W• Material - High Strength Polycarbonate

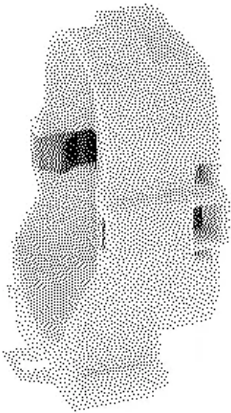

Type
UPC

- Mounting - Horizontal, screw-down
- Compact Fluorescent
883778303968

Electrical Ratings

Connectivity	Screw Terminals
Current Rating	Telephone/CATV
Frequency Rating	60 Hz
Voltage Rating	600V AC kV

Certifications And Compliance

Industry Standard(s)	<ul style="list-style-type: none">• C/US UL Listed• CSA Certified
----------------------	--

Logistics

Carton Quantity	10
-----------------	----

Product Assets

- [Catalog Page - WDK BB-7 Catalog Page](#)
[Catalogs - WDK Catalog Full 2024](#)
[Installation Manuals - WIRING_PD2365_INSTALLINST](#)
[Sales Drawings - WDK_RL42G11HSM_DRAWING_PDF](#)
[Specifications - RL42G11HSM Specification Sheet French](#)
[Specifications - RL42G11HSM Specification Sheet](#)
[Specifications - WIRING_RL42G11HSM_spec](#)
[Warranty - tradeSELECT™ and netSELECT®](#)



A Hubbell brand