


RMS100ILI

By Hubbell Wiring Device-Kellems
Catalog # [RMS100ILI](#)

VAC SENSOR SW ILLUM, 500W 125V,IV

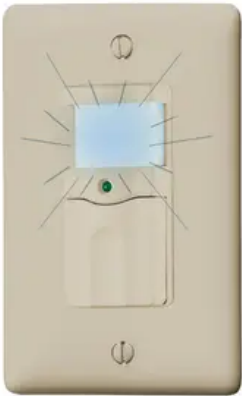

Application

1-Button

General

Catalog Number	RMS100ILI
Control Output	Input Voltage
EU RoHS Indicator	Contact Manufacturer
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Indicator(s) Type	PIR= Red LED
Item Type	Residential Wall Switches
Load Capacity	500W Incandescent @ 120V AC
Material - Mounting Hardware	Screw Mounting
Operating Cycles	6,000 Cycles Minimum
Operating Temperature	32 Deg F to 104 Deg F (0 Deg C to 40 Deg C)

Sensing Range	42 to 54 Inches above the Floor
UPC	883778301124

Electrical Ratings

Sensitivity	Adjustable W
Supply Voltage	120V AC V

Logistics

Carton Quantity	10
-----------------	----

Product Assets

- [Catalogs - WDK Catalog Full 2024](#)
- [Engineering Drawing - RMS100ILI AutoCAD Drawing](#)
- [Installation Manuals - WIRING_PD2203_INSTALLINST](#)
- [Sales Drawings - WDK_RMS100_DRAWING_PDF](#)
- [Specifications - RMS100ILI Specification Sheet English](#)
- [Specifications - RMS100ILI Specification Sheet French](#)