

RMS120ILLA

By Hubbell Wiring Device-Kellems  
Catalog # [RMS120ILLA](#)


Trade Select, Switches and Lighting Controls, Occupancy Sensor  
With Night Light, Dimming, 500 Watts, 120V AC, 150 Degree  
Field of View, Single Pole, Light Almond

Application

No Buttons

General

Catalog Number	RMS120ILLA
Control Output	Input Voltage
EU RoHS Indicator	No
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Indicator(s) Type	PIR= Red LED
Item Type	Residential Wall Switches
Load Capacity	500W Incandescent @ 120V AC
Material - Mounting Hardware	Screw Mounting
Operating Cycles	6,000 Cycles Minimum
Operating Temperature	32 Deg F to 104 Deg F (0 Deg C to 40 Deg C)
Sensing Range	42 to 54 Inches above the Floor
Specifications	<ul style="list-style-type: none"><li>Product Type - Dimming Control Sensors</li></ul>

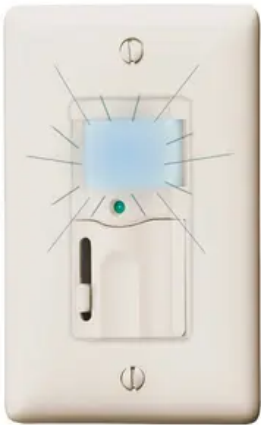

UPC

- Style - w/ Nightlight  
883778301179

Electrical Ratings

Sensitivity	Adjustable W
Supply Voltage	120V AC V

Certifications And Compliance

Industry Standard(s)	<ul style="list-style-type: none"><li>CEC Title 24 Certified</li><li>cULus Listed</li></ul>
----------------------	---

Logistics

Carton Quantity	10
-----------------	----

Product Assets

- [Catalogs - WDK Catalog Full 2024](#)
- [Engineering Drawing - RMS120ILLA AutoCAD Drawing](#)
- [Installation Manuals - WIRING\\_PD2203\\_INSTALLINST](#)
- [Sales Drawings - WDK\\_RMS120\\_DRAWING\\_PDF](#)
- [Specifications - RMS120ILLA Specification Sheet French](#)
- [Specifications - RMS120ILLA Specification Sheet English](#)