


RMS121ILAL

By Hubbell Wiring Device-Kellems  
Catalog # [RMS121ILAL](#)

Trade Select, Switches and Lighting Controls,Occupancy Sensor,  
Wall Mounted, 500 Watt, 125V, Illuminated with Dimming,  
Almond.

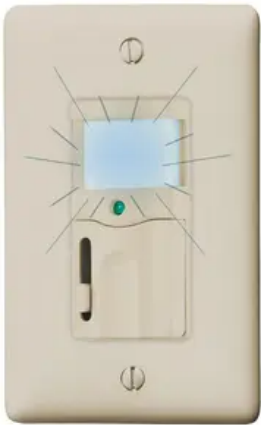

Application

No Buttons

General

Catalog Number	RMS121ILAL
Control Output	Input Voltage
EU RoHS Indicator	Contact Manufacturer
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Indicator(s) Type	PIR= Red LED
Item Type	Residential Wall Switches
Load Capacity	500W Incandescent @ 120V AC
Material - Mounting Hardware	Screw Mounting
Operating Cycles	6,000 Cycles Minimum
Operating Temperature	32 Deg F to 104 Deg F (0 Deg C to 40 Deg C)

Sensing Range	42 to 54 Inches above the Floor
UPC	883778301230

Electrical Ratings

Sensitivity	Adjustable W
Supply Voltage	120V AC V

Logistics

Carton Quantity	10
-----------------	----

Product Assets

- [Catalogs - WDK Catalog Full 2024](#)
- [Engineering Drawing - RMS121ILAL AutoCAD Drawing](#)
- [Installation Manuals - WIRING\\_PD2203\\_INSTALLINST](#)
- [Sales Drawings - WDK\\_RMS121\\_DRAWING\\_PDF](#)
- [Specifications - RMS121ILAL Specification Sheet French](#)
- [Specifications - RMS121ILAL Specification Sheet English](#)