

TradeSelect, Straight Blade,
SingleReceptacle, Snap-In, 15A
125V, 2-Pole 3-Wire, 5-15, White

By Hubbell Wiring Device-Kellems
Catalog # [RR374W](#)

TradeSelect, Straight Blade, SingleReceptacle, Snap-In, 15A 125V,
2-Pole 3-Wire, 5-15, White

Features

- Panel cutout .95 x .95 inch (24.1 x 24.1 mm)
- Accommodate panel thickness of .031 to .062 inch (0.7 to 1.5 mm)

Performance

Mechanical - Terminal Accommodation - #14 AWG 6 inch
AWM/TEW FT1 105°C 600V on black and white leads, #14 AWG
6 inch AWM/TEW FT1 600V on green lead

General


Catalog Number	RR374W
EU RoHS Indicator	No
Item Type	Snap-In Receptacles
Material	Thermoplastic
Material - Mounting Hardware	Snap-In
Number Of Poles	2-Pole
Series	Lampholder Accessories
UPC	883778304231

Dimensions

Display Size	Standard Sized Product
--------------	------------------------

Electrical Ratings

Amperage Rating	15 A
-----------------	------

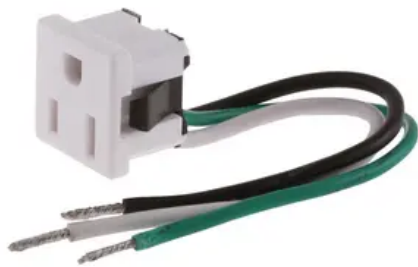

Connectivity	Pressure Terminal Screws
Current / Amperage Rating	15 A
Current Rating	15 A
Phase	Single Phase
Voltage Rating	125 VAC
Wattage	1875

Conductor Related

Number Of Wires	3-Wire Grounding
Wire Size	#16 AWG to #14 AWG

Certifications And Compliance

Nema Rating	5-15R
-------------	-------

Logistics

Carton Quantity	10
-----------------	----

Product Assets

- [Catalog Page - WDK BB-9 Catalog Page](#)
- [Catalogs - WDK Catalog Full 2024](#)
- [Installation Manuals - WIRING_PD2369_INSTALLINST](#)
- [Sales Drawings - WDK_RR374W_DRAWING_PDF](#)
- [Specifications - WIRING_RR374W_spec](#)
- [Specifications - RR374W Specification Sheet](#)
- [Specifications - RR374W Specification Sheet French](#)
- [Warranty - tradeSELECT™ and netSELECT®](#)