


Wallplates and Boxes, Metallic
Plates, 2- Gang, 1) 1.40" Opening,
Standard Size, Stainless Steel

By Hubbell Wiring Device-Kellems
Catalog # [SS747](#)

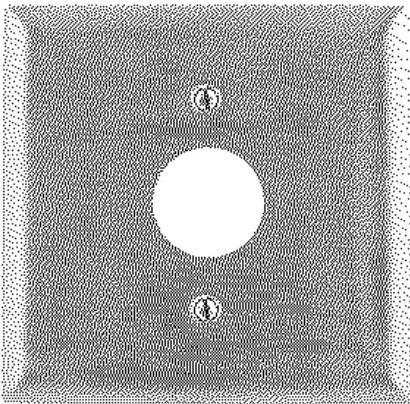

Wallplates and Boxes, Metallic Plates, 2- Gang, 1) 1.40" Opening,
Standard Size, Stainless Steel

Features

- Ideal for highly corrosive environments
- Non-magnetic
- Protective plastic film helps to prevent scratches and damage

Application

Protection against contact of live terminals and wiring. Provides
finished look to installation.

General

Catalog Number	SS747
Construction	Stamped
Cutout	1) 1.40" Opening
EU RoHS Indicator	Yes
Item Type	Screw Mount
Material	Stainless Steel, Type 302/304
Material - Mounting Hardware	Screw Mounting
Number of Gang(s)	2-Gang
Orientation	Vertical Mount
Size	Standard
Specifications	<ul style="list-style-type: none">• Appearance - Horizontal brushed appearance• Mounting Screws - 302/304 SS, Slotted head• Plate Material - Stainless steel 302/304

Style
Type
UPC

- Plate Openings - Single Receptacle
 - Plate Type - 2-Gang
- 1-Single - 1.40 in. Hole
Single
883778201240

Dimensions

Display Size	Standard Sized
Thickness	0.035

Certifications And Compliance

Industry Standard(s)	UL Listed
Standards - RoHS Compliance Status	CM

Logistics

Carton Quantity	10
-----------------	----

Product Assets

- [Catalog Page - WDK N-7 Catalog Page](#)
- [Catalogs - WDK Catalog Full 2024](#)
- [Specifications - Wiring SS747 Specification Sheet](#)
- [Specifications - SS747 Specification Sheet French](#)
- [Specifications - SS747 Specification Sheet](#)
- [Warranty - Industrial & Commercial Products](#)