


Locking Devices, Twist-Lock®, Industrial, Receptacle, 50A 3-Phase Delta 250V AC, 3-Pole 4-Wire Grounding, Non-NEMA, Screw Terminal, Black

By Hubbell Wiring Device-Kellems
Catalog # [CS8369](#)

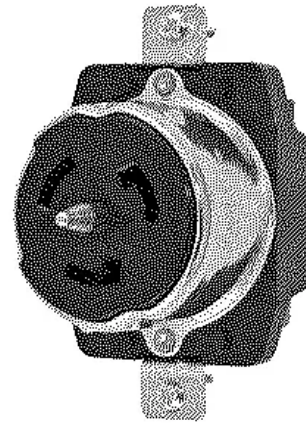

Locking Devices, Twist-Lock®, Industrial, Receptacle, 50A 3-Phase Delta 250V AC, 3-Pole 4-Wire Grounding, Non-NEMA, Screw Terminal, Black

Performance

- Electrical - Current Interrupting - Certified for current interrupting at full rated current
- Electrical - Dielectric Voltage - Withstands 2,000V minimum
- Environmental - Flammability - UL 94 V0
- Environmental - Operating Temperatures - Maximum continuous 75°C minimum -40°C (w/o impact)
- Mechanical - Terminal Accommodation - #10 AWG - #6 AWG solid or stranded copper wire only

General

Catalog Number	CS8369
EU RoHS Indicator	No
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	Receptacles
Material	Phenolic
Material - Mounting Hardware	Screw Mounting
Number Of Poles	3-Pole
Operating Temperature	Maximum continuous 75°C and minimum -40°C without Impact
Specifications	<ul style="list-style-type: none">• Body - Phenolic• Contacts - Brass• Face - Phenolic• Insulator - Phenolic• Terminal Screws - Steel
Type	Receptacle
UPC	783585829074

Dimensions

Dimensions	2.69 in x 2.12 in x 2.36 in
Display Size	Standard Sized Product

Height	2.36 in
Length	2.69 in
Weight	0.75 lb
Width	2.12 in

Electrical Ratings

Amperage Rating	50 A
Connectivity	Screw Terminals
Current / Amperage Rating	50 A
Current Rating	50 A
Dielectric Strength	Withstands 2,000V minimum
Phase	Three Phase
Voltage Rating	3-Phase Delta 250 VAC
Voltage Rating Description	3-Phase Delta 250 VAC

Conductor Related

Number Of Wires	4-Wire
Wire Size	#10 AWG to #6 AWG

Certifications And Compliance

Industry Standard(s)	<ul style="list-style-type: none">• Certified to CSA C22.2 No.42• Listed to UL 498
----------------------	---

Logistics

Carton Quantity	1
Pallet Quantity	1680

Product Assets

[Catalogs - WDK Catalog Full 2024](#)
[Specifications - CS8369](#)
[Warranty - Industrial & Commercial Products](#)