




Wiring Device-Kellems

# Wallplates and Boxes, Marine Products, 24-32V DC, Connector Body, For Trolling Motor, Yellow, Corrosion Resistant

By Hubbell Wiring Device-Kellems  
Catalog # [HBL328DCC](#)

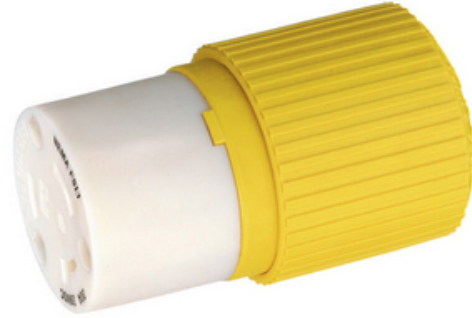

Marine 24-32V DC, Connector Body, for Trolling Motor, Corrosion Resistant

## Application

Marine Wiring Devices

## General

Color	Yellow
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Insulation	Insulated Body
Item Type	Standard
Material	Composite
Material - Mounting Hardware	Cord Mounted
Number Of Poles	2-Pole
Temperature Rating	Maximum Continuous: 75° C; Minimum Continuous: -40° C w/o impact, -25° with impact.
UPC	783585353142

## Dimensions

Display Size	Standard
--------------	----------

## Electrical Ratings

Amperage Rating	30 A
Connectivity	Screw Terminals
Current / Amperage Rating	30 A
Current Rating	30 A
Voltage Rating	28V DC kV

## Conductor Related

Conductor Range	#14 AWG to #10 AWG
Number Of Conductors	3-Wire Grounding

## Certifications and Compliance

Industry Standard(s)	UL Listed
Nema Rating	Non-NEMA
Standards - RoHS Compliance Status	CM

## Logistics

Carton Quantity	10
-----------------	----

## Product Assets

- [Catalog Page - Wiring\\_Catalog\\_BB34\\_CatPage](#)
- [Catalogs - WDK Catalog Full 2023](#)
- [Warranty - Industrial & Commercial Products](#)



A proud member of the Hubbell Family.