


Locking Devices, Midget Twist-Lock®, Valise®, Female Connector Body, 15A 125V AC, 2-Pole 2-Wire Non Grounding, NEMA ML- 1R, Screw Terminal, Polarized.

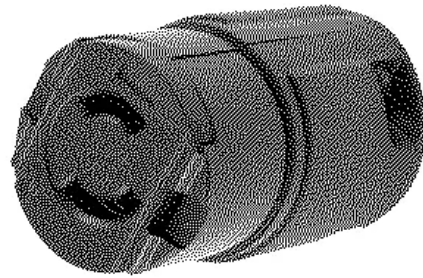

By Hubbell Wiring Device-Kellems
Catalog # [HBL7464V](#)

Locking Devices, Midget Twist-Lock®, Valise®, Female Connector Body, 15A 125V AC, 2-Pole 2-Wire Non Grounding, NEMA ML- 1R, Screw Terminal, Black, Polarized.

Performance

- Electrical - Current Interrupting - Certified for current interrupting at full rated current
- Electrical - Dielectric Voltage - Withstands 2,000V minimum
- Environmental - Flammability - HB or better per UL94/CSA 22.2 No.0.17
- Environmental - Moisture Resistance - IP20 Suitability
- Environmental - Operating Temperatures - Maximum Continuous 75°C Minimum -40°C (w/o impact)
- Mechanical - Terminal Accomodation - #18 AWG - #14 AWG stranded copper wire only.
- Mechanical - Terminal Identification - Terminals identified in accordance with UL 498

General

Catalog Number	HBL7464V
Cord Range	0.220"-0.385"(5.6-9.8)
EU RoHS Indicator	Yes
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Insulation	Insulated Body
Item Type	15A Midget Twist-Lock® Valise® Connector
Material	Nylon
Material - Mounting Hardware	Cord Mounted
Number Of Poles	2-Pole
Operating Temperature	Maximum continuous 75°C and minimum -40°C without Impact
Specifications	<ul style="list-style-type: none"> • Body Holding Screws - Steel - Zinc plated • Contacts - Brass • Housing - Nylon • Terminal Clamps - Steel - Nickel plated • Terminal Screws - #6 - 32 Steel (Philips / Slotted / Robertson)

Temperature Rating

Maximum Continuous: 75° C;
Minimum Continuous: -40° C w/o impact, -25° with impact.
Connector Body
783585237251

Type
UPC

Dimensions

Dimensions	1.06 in x 1.06 in x 1.77 in
Display Size	Midget Locking
Height	1.77 in
Length	1.06 in
Weight	0.05 lb
Width	1.06 in

Electrical Ratings

Amperage Rating	15 A
Connectivity	Pressure Terminal Screws
Current / Amperage Rating	15 A
Current Rating	15 A
Dielectric Strength	Withstands 2,000V minimum
Voltage Rating	125 V
Voltage Rating Description	125 V

Conductor Related

Cable Range	0.220 - 0.385 in
Conductor Range	#14 AWG to #12 AWG
Number Of Wires	2-Wire
Wire Size	#18 AWG to #14 AWG

Certifications And Compliance

Industry Standard(s)	<ul style="list-style-type: none"> • Certified to CSA C22.2 No.42 • Listed to UL 498
Nema Rating	ML-1R
Standards - RoHS Compliance Status	CM

Logistics

Carton Quantity 10
Pallet Quantity 7800

Product Assets

[Catalogs - WDK Catalog Full 2024](#)
[Specifications - HBL7464V](#)
[Warranty - Industrial & Commercial Products](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
WDK_MX-HBL7464V-SPEC-EN | REV 10/2024