




# Locking Devices, Twist-Lock®, Industrial, Male Plug, 10A 250V/15A 125V, 3-Pole 3-Wire Non-Grounding, Non-NEMA, Screw Terminal, Black and White

By Hubbell Wiring Device-Kellems  
Catalog # [HBL7567C](#)

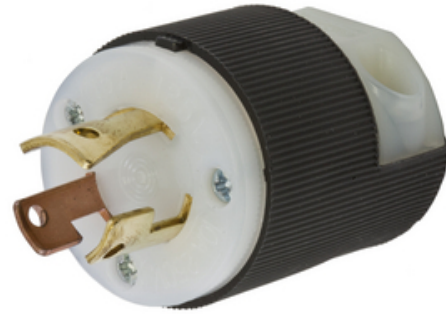

Locking Devices, Twist-Lock®, Insulgrip® Plug, 10A, 250V/15A, 125V, 3 Pole, 3 Wire Non-Grounding, Non-NEMA, Multiple drive screws, Black and white nylon

## Features

- Individually molded face for each blade configuration keeps debris out of plug interior
- Ribbed nylon housing is impact and chemical resistant
- Roomy wiring chamber provides ample space for wiring

## Application

Extra Heavy Duty Industrial

## General

Color	Black, White
Cord Range	0.230"-0.720"(5.8-18.3)
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	10A/15A Insulgrip® Plug
Listings	<ul style="list-style-type: none"> <li>• Fed.Spec. W-C-596</li> <li>• CSA C22.2 No.42</li> </ul>
Material	Nylon
Material - Mounting Hardware	Cord Mounted
Number Of Poles	3-Pole
Operating Temperature	Maximum continuous 75°C and minimum -40°C without Impact
Performance	<ul style="list-style-type: none"> <li>• Electrical-Current Interrupting - Certified for current interrupting at full rated current</li> <li>• Electrical - Dielectric Voltage - Withstands 2,000V minimum</li> <li>• Mechanical - Terminal Accommodation - #18 - #10 AWG stranded copper wire only</li> <li>• Mechanical - Terminal Identification - Terminals identified in accordance with UL 498</li> <li>• Environmental - Flammability - HB or better per UL94/CSA 22.2 No.0.17</li> </ul>

## Dimensions

Dimensions	1.53 in x 1.53 in x 1.97 in
Display Size	Standard Sized
Height	1.97 in
Length	1.53 in
Weight	0.15 lb
Width	1.53 in

## Electrical Ratings

Amperage Rating	10 A
Connectivity	Screw Terminals
Current / Amperage Rating	10 A
Current Rating	10 A
Dielectric Strength	Withstands 2,000V minimum
Phase	Single Phase
Voltage Rating	250/125 V
Voltage Rating Description	250/125 V

## Conductor Related

Cord Type	All Listed Portables
Number Of Wires	3-Wire Non-Grounding
Wire Size	#18 AWG to #10 AWG

## Certifications and Compliance

Industry Standard(s)	<ul style="list-style-type: none"> <li>• Certified to CSA C22.2 No.42</li> <li>• Fed.Spec.W-C-596</li> </ul>
----------------------	--

Nema Rating	Non-NEMA
Standards - RoHS Compliance Status	CM

## Logistics

Carton Quantity	10
-----------------	----

## Product Assets

[Catalogs - WDK Catalog Full 2023](#)  
[Warranty - Industrial & Commercial Products](#)

- Environmental - Moisture Resistance - IP20 Suitability
- Environmental - Operating Temperatures - Maximum Continuous 75°C
- Minimum -40°C (w/o impact)

UPC

783585178752



**A proud member of the Hubbell Family.**

©2024 Hubbell Incorporated. All rights reserved.  
WDK\_MX-HBL7567C-SPEC-EN | REV 1/2024