




Straight Blade Devices, Male Plug, Insulgrip, Hospital Grade, Straight, 2-Pole 3-Wire Grounding, 15A 125V, 5-15P, Black and White, Single Pack

By Hubbell Wiring Device-Kellems
Catalog # [HBL8215C](#)

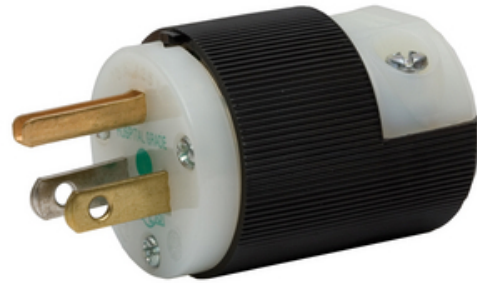

Straight Blade Devices, Male Plug, Insulgrip, Hospital Grade, Straight, 2-Pole 3-Wire Grounding, 15A 125V, 5-15P, Black and White , Single Pack.

Features

- Beveled housing prevents snagging
- Powerful, offsetting cord grips clamp on individual conductors

Application

Hospital Grade

General

Color	<ul style="list-style-type: none"> • Black and White • Noir, blanc
Cord Range	0.230"-0.720" (5.8-18.3)
Horsepower - Maximum	0.5
Item Type	Insulgrip Plug
Material	Nylon
Number Of Poles	2-Pole
Operating Temperature	Maximum continuous 75°C and minimum -40°C without Impact
Performance	<ul style="list-style-type: none"> • Electrical - Current Interrupting - Certified for current interrupting at full rated current • Electrical - Dielectric Voltage - Withstands 2000V AC minimum • Environmental - Flammability - UL 94 HB or better • Environmental - IP Suitability - IP20 • Environmental - Operating Temperatures - Maximum continuous 75°C, minimum -40°C (w/o impact) • Mechanical - Product Identification - Ratings are a permanent part of the device • Mechanical - Terminal Accommodation - #18-10 AWG • Mechanical - Terminal

Dimensions

Dimensions	1.97 in x 1.53 in x 1.53 in
Height	1.53 in
Length	1.97 in
Weight	0.15 lb
Width	1.53 in

Electrical Ratings

Amperage Rating	15 A
Current / Amperage Rating	15 A
Current Rating	15 A
Dielectric Strength	Withstands 2,000V minimum
Voltage Rating	125 V
Voltage Rating Description	125 V

Conductor Related

Number Of Wires	3-Wire
Wire Size	#18 AWG to #10 AWG

Certifications and Compliance

Industry Standard(s)	<ul style="list-style-type: none"> • Certified to CSA, C22.2, No. 42 File 285 • Fed. Spec. W-C-596 • UL Listed to UL498 File No. E2186
----------------------	---

Nema Rating	5-15P
Standards - RoHS Compliance Status	CM

Logistics

Carton Quantity	10
-----------------	----

Product Assets

[Catalogs - WDK Catalog Full 2023](#)
[Literature - Healthcare Product Solutions](#)
[Warranty - Industrial & Commercial Products](#)

Identification - Terminals
identified in accordance
with UL 498 and CSA

Series	Hospital Grade
Style	Insulgrip
Type	<ul style="list-style-type: none">• Plug• Plug
UPC	783585179209



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.
WDK_MX-HBL8215C-SPEC-EN | REV 1/2024