


**HUBBELL**  
Wiring Device-Kellems

**Heavy Duty Products, IEC Pin and  
Sleeve Devices, Marine Grade,  
Female, Receptacle, 100A  
125/250V, 3-Pole 4-Wire  
Grounding, Terminal Screws, Yellow**

By Hubbell Wiring Device-Kellems  
Catalog # [M4100R12](#)

Heavy Duty Products, IEC Pin and Sleeve Devices, Marine Grade,  
Female, Receptacle, 100A 125/250V, 3-Pole 4-Wire Grounding,  
Terminal Screws, Yellow

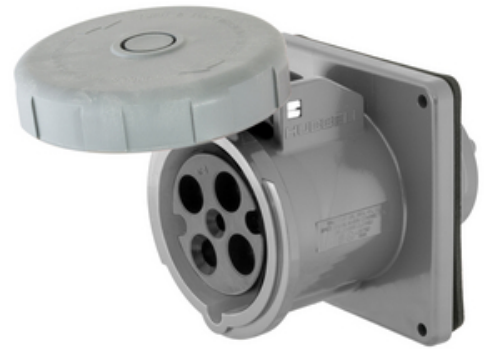

## General

Application	Marine Wiring Devices
Catalog Number	M4100R12
Color	Gray
EU RoHS Indicator	Yes
Environmental Conditions	Weather Resistant
Item Type	Single
Material	Thermoplastic
Material - Mounting Hardware	Screw Mounting
Number Of Poles	3-Pole
Performance	Electrical - Current Interrupting - Certified for current interrupting at full rated current
	Electrical - Dielectric Voltage - Withstand 3000V AC
	Electrical - Max. Working Voltage - 600V RMS
	Environmental - Flammability - HB or better per UL 94 or CSA C22.2 No. 0.17
	Environmental - Ingress Protection - IP67 Suitability
	Environmental - Moisture Resistance - Watertight per IEC 60309-1
	Environmental - Operating Temperatures - Maximum Continuous 75°C
	Minimum - 40°C w/o impact
	Mechanical - Impact Resistance - Per CSA C22.2 No. 182.1 / UL1682
	Mechanical - Product Identification - Ratings are a permanent part of the device housing
	Mechanical - Terminal Identification - Terminals identified in accordance with North American and IEC conventions
Series	Corrosion Resistant
Style	Standard Service
Type	Watertight Receptacle
UPC	783585410050

## Dimensions

Display Size	Standard Sized Product
--------------	------------------------

## Electrical Ratings

Amperage Rating	100 A
Connectivity	Pressure Terminal Screws
Current / Amperage Rating	100 A
Current Rating	100 A
Phase	Single Phase
Voltage Rating	125/250 VAC
Voltage Rating Description	125/250 VAC
Wattage	25000

## Conductor Related

Number Of Wires	4-Wire
Wire Size	#3 AWG to #1/0 AWG

## Certifications And Compliance

Industry Standard(s)	CSA Standard C22.2 No. 182.1 UL Classified to IEC 60309-1 IEC 60309-2 UL Listed, File E146032
Nema Rating	Non-NEMA

## Logistics

Carton Quantity	6
-----------------	---

## Product Assets

[Catalogs - WDK Catalog Full 2024](#)  
[Warranty - Industrial & Commercial Products](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved  
WDK\_MX-M4100R12-SPEC-EN | REV 6/2024