


2-Gang Flat Flange with Grounding Wire with Grounding Wire, Rectangular, 6.00" X 8.14", Brushed Aluminum

By Hubbell Wiring Device-Kellems
Catalog # [SA3084W](#)

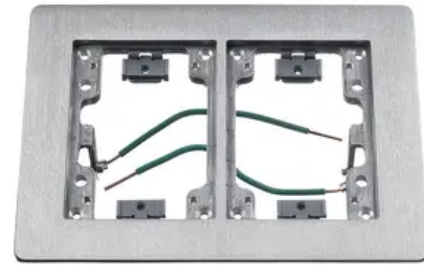

Flush Concrete Floor Box Series, 2-Gang Flat Flange with
Grounding Wire with Grounding Wire, Rectangular, 6.00" X 8.14",
Brushed Aluminum

Application

- In-Floor Delivery Systems

General

Application - For Use On	Carpet; Tile; Concrete; Wood
Catalog Number	SA3084W
Color	Aluminum
Construction	Machined
EU RoHS Indicator	No
Finish Type	Aluminum
Item Type	Rectangular Floor Flange
Material - Mounting Hardware	Screw Mounting
Mounting Method	Screw Mount
Series	<ul style="list-style-type: none">Flush Rectangular - PFB SeriesFlush Rectangular - B24 Series
Size	1-Gang;2-Gang;3-Gang
Specifications	<ul style="list-style-type: none">Box Version - RectangularDimensions - 6.00" x 8.13"No. of Gangs - 2-Gang
Type	Rectangular Floor Flange
Type of Use	Carpet, Tile
UPC	783585854052

Dimensions

Dimensions	8.13 in x 6 in x 2 in
Display Size	2-Gang
Height	2 in
Length	8.13 in
Width	6 in

Certifications And Compliance

Industry Standard(s)	<ul style="list-style-type: none">UL/CSAUL514
----------------------	--

Logistics

Carton Quantity	10
Pallet Quantity	550

Product Assets

[Brochures - Floorbox Selection Guide](#)
[Catalogs - WDK Catalog Full 2024](#)
[Literature - Rectangular Stamped Steel Floor Boxes](#)
[Literature - Rectangular Cast Iron Floor Boxes](#)
[Specifications - SA3084W](#)
[Warranty - Industrial & Commercial Products](#)