




# N12 22.5 MM 4 Pushbutton Enclosure 8.8X2.7X3.5 304 Stainless Steel

By Wiegmann  
Catalog # [PBGX4SS](#)

N12 22.5 MM 4 Pushbutton Enclosure 8.8X2.7X3.5 304 Stainless Steel

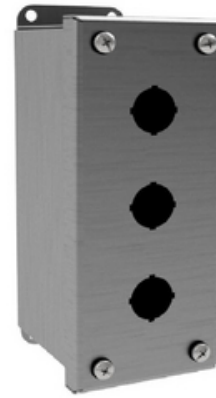

\*Representative Image

## General

Application	Designed to hold all standard brands of miniature 22MM oil-tight pushbuttons, switches and pilot lights. Provides protection from dust, dirt and water. Great for corrosive environments as well.
Construction	Continuously Welded Seams
Cover Type	Pushbutton;Screw
EU RoHS Indicator	Yes
Material	304 Stainless Steel
Mounting Type	External Mounting Plates
Number of Holes	4
Series	PBGX_SS
Type	Miniature Pushbutton Enclosure
UPC	786725891214

## Dimensions

Actual Depth	3.5 in
Actual Height	8.88 in
Actual Width	2.75 in
Depth	4 in
Height	9 in
Weight	4 lb
Width	3 in

## Certifications And Compliance

Certified Listed	cULus
Industry Standard(s)	UL508A, Type 4, 4X, 12 & 13 cULus Certified Type 4, 4X, 12 & 13 UL Files E64791
Nema Rating	NEMA Type 4, 4X, 12 and 13
UL Listed	Yes

## Logistics

Carton Quantity	1
-----------------	---

## Product Assets

- [3D Models - PBGX4](#)
- [Catalogs - Wiegmann Operator Interface](#)
- [Catalogs - Wiegmann Stainless Steel & Aluminium](#)
- [Customer Notices - Prop 65 - Cancer & Reproductive Harm Notice](#)
- [Engineering Drawing - HWDPBGX4-S](#)
- [Sales Drawings - HWDPBGX4-S](#)
- [SDS - HCC SDS](#)
- [Sell Sheets - Stainless Steel Pushbutton Enclosures](#)
- [Terms and Conditions - HCC Terms & Conditions](#)



**A Hubbell brand**

©2024 Hubbell Incorporated. All rights reserved  
WIEG-PBGX4SS-SPEC-EN | REV 6/2024