




N12 22.5 MM 4 Pushbutton Enclosure 8.8X2.7X3.5 316 Stainless Steel

By Wiegmann
Catalog # [PBGX4SSA](#)

N12 22.5 MM 4 Pushbutton Enclosure 8.8X2.7X3.5 316 Stainless Steel

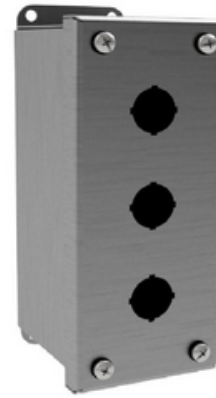

*Representative Image

General

| | |
|-------------------|---|
| Application | Designed to hold all standard brands of miniature 22MM oil-tight pushbuttons, switches and pilot lights. Provides protection from dust, dirt and water. Great for corrosive environments as well. |
| Construction | Continuously Welded Seams |
| Cover Type | Pushbutton;Screw |
| EU RoHS Indicator | Yes |
| Material | 316 Stainless Steel |
| Mounting Type | External Mounting Plates |
| Number of Holes | 4 |
| Series | PBGX_SSA |
| Type | Miniature Pushbutton Enclosure |
| UPC | 786725891269 |

Dimensions

| | |
|---------------|---------|
| Actual Depth | 3.5 in |
| Actual Height | 8.88 in |
| Actual Width | 2.75 in |
| Depth | 4 in |
| Height | 9 in |
| Weight | 4 lb |
| Width | 3 in |

Certifications And Compliance

| | |
|----------------------|---|
| Certified Listed | cULus |
| Industry Standard(s) | UL508A, Type 4, 4X, 12 & 13 cULus Certified Type 4, 4X, 12 & 13 UL Files E64791 |
| Nema Rating | NEMA Type 4, 4X, 12 and 13 |
| UL Listed | Yes |

Logistics

| | |
|-----------------|---|
| Carton Quantity | 1 |
|-----------------|---|

Product Assets

- [3D Models - PBGX4](#)
- [Catalogs - Wiegmann Operator Interface](#)
- [Catalogs - Wiegmann Stainless Steel & Aluminium](#)
- [Customer Notices - Prop 65 - Cancer & Reproductive Harm Notice](#)
- [Engineering Drawing - HWDPBGX4-S](#)
- [Sales Drawings - HWDPBGX4-S](#)
- [SDS - HCC SDS](#)
- [Sell Sheets - Stainless Steel Pushbutton Enclosures](#)
- [Terms and Conditions - HCC Terms & Conditions](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
WIEG-PBGX4SSA-SPEC-EN | REV 6/2024