




N12 22.5 MM 6 Pushbutton Enclosure 8.5X5X4.2 316 Stainless Steel

By Wiegmann
Catalog # [PBGX6SSA](#)

N12 22.5 MM 6 Pushbutton Enclosure 8.5X5X4.2 316 Stainless Steel

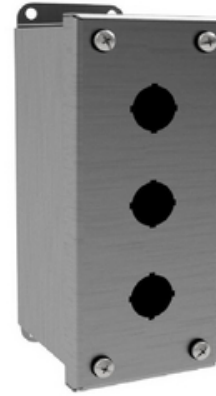

*Representative Image

General

Application	Designed to hold all standard brands of miniature 22MM oil-tight pushbuttons, switches and pilot lights. Provides protection from dust, dirt and water. Great for corrosive environments as well.
Construction	Continuously Welded Seams
Cover Type	Pushbutton;Screw
EU RoHS Indicator	Yes
Material	316 Stainless Steel
Mounting Type	External Mounting Plates
Number of Holes	6
Series	PBGX_SSA
Type	Miniature Pushbutton Enclosure
UPC	786725891276

Dimensions

Actual Depth	4.25 in
Actual Height	8.5 in
Depth	4 in
Height	9 in
Weight	5 lb
Width	5 in

Certifications And Compliance

Certified Listed Industry Standard(s)	cULus UL508A, Type 4, 4X, 12 & 13 cULus Certified Type 4, 4X, 12 & 13 UL Files E64791
Nema Rating UL Listed	NEMA Type 4, 4X, 12 and 13 Yes

Product Assets

- [3D Models - PBGX6](#)
- [Catalogs - Wiegmann Operator Interface](#)
- [Catalogs - Wiegmann Stainless Steel & Aluminium](#)
- [Customer Notices - Prop 65 - Cancer & Reproductive Harm Notice](#)
- [Engineering Drawing - HWDPBGX6-S](#)
- [Sales Drawings - HWDPBGX6-S](#)
- [SDS - HCC SDS](#)
- [Sell Sheets - Stainless Steel Pushbutton Enclosures](#)
- [Terms and Conditions - HCC Terms & Conditions](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
WIEG_CA-PBGX6SSA-SPEC-EN | REV 6/2024