

Single Pole Devices and Temporary Power

400A, 600V Series 16

Extended Stud Type Male Receptacles

HUBBELL

Ordering Information

| Description | Device Color | UPC | Catalog Number |
|---|--------------|--------------|----------------|
| 400 A, Panel Mount, thermoplastic elastomer, mates with 300 and 400A connectors | Black | 783585528427 | HBLMRSCEBK |



Standards

UL and cUL Listed
UL Enclosure Types 3R, 4X, 12
National Electric Code (NEC), ANSI/NFPA 70

Specifications


| | |
|--------------------------|-----------------------------|
| Base Compound | Thermoplastic Elastomer |
| Contact Material | Brass |
| Retaining Screw Material | Nylon |
| Mounting Hole | 4x \varnothing .20" |
| Termination | 1/2-13 UNC-2A Threaded Stud |

Performance

| Electrical | |
|-----------------|--------------|
| Amperage Rating | 400A Maximum |
| Voltage Ratings | 600V Maximum |

| Mechanical | |
|------------------------|--|
| Product Identification | Ratings are a permanent part of device |

| Environmental | |
|---------------|-------------------------------|
| Flammability | HB per UL94 or CSA 22.2. 0.17 |

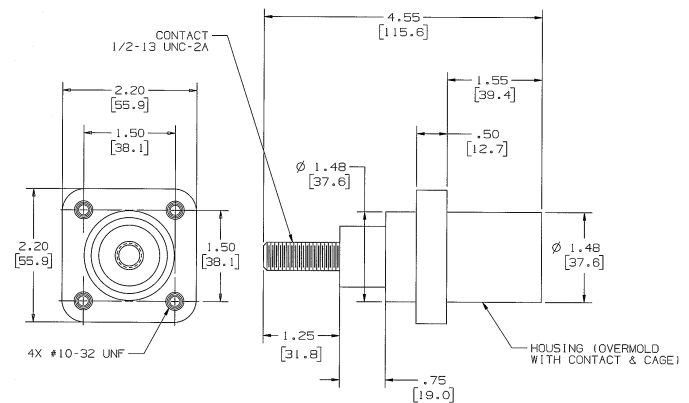

Online Resources

Customer Use Drawing
eCatalog
Installation Instructions

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

