

Kellems® Wire Management Products

Strain Relief Grips

Deluxe Cord Grips



- Features
- Stainless steel mesh is corrosion resistant
 - Multiweave grip gives cable arc-of-bend control
 - Endless weave provides easy cable/flexible conduit installation

Ordering Information

Description	Form Size	Cable	UPC	Catalog Number
Straight Male Thread, F6 Stainless Steel Mesh, Liquidtight		1.250"-1.375" (3.17-3.49)	783585330860	074011258




Listings

UL Listed
CSA Certified

Specifications

Strand	Stainless Steel
Body	Aluminum

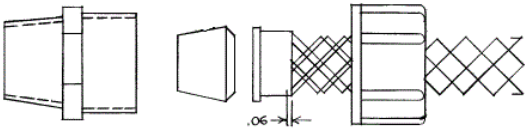

Performance

Environmental	UL 94HB (Strand grip), UL 94V-2(Fitting)
Flammability	Suitable for use in hazardous locations per Class I Div. 2, Class II Div. 1 & 2, Class III Div. 1 & 2 N.E.C
Hazardous Locations	
Operating Temperatures	–30°F to +240°F (–34°C to +115°C)
Wet Locations	Suitable for use in wet locations when used with a listed sealing ring between box and fitting

Related Products

Metal Clad Sealing O-Ring	20509006
---------------------------	----------

Online Resources

Customer Sales Drawings
eCatalog
Installation Instructions

