

Kellems® Wire Management Products

Strain Relief Grips

Deluxe Cord Grips

Features

- Aluminum Fitting
- Stainless steel mesh is corrosion resistant
- Neoprene bushing is oil and watertight

Ordering Information

Description	Form Size	Cable	UPC	Catalog Number
90° Male Thread, Liquidtight, for Insulated Cables	F3	.375"-1.500" (.95-1.27)	783585331201	074011349

Listings

UL Listed
CSA Certified


Specifications

Strand	Stainless Steel
Body	Nylon

Performance

Environmental	
Flammability	UL 94HB (Strand grip), UL 94V-2(Fitting)
Hazardous Locations	Suitable for use in hazardous locations per Class I Div. 2, Class II Div. 1 & 2, Class III Div. 1 & 2 N.E.C
Operating Temperatures	−40°F to +225°F (−40°C to +107°C)
Wet Locations	Suitable for use in wet locations when used with a listed sealing ring between box and fitting

HUBBELL

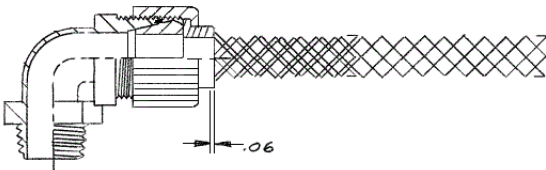

Related Products

Locknut	00322002LPK50
Metal Clad Sealing O-Ring	20509002

Online Resources

Customer Sales Drawings
eCatalog

