

Kellems® Wire Management Products

Strain Relief Grips

Deluxe Cord Grips

Features

- Aluminum Fitting
- Stainless steel mesh is corrosion resistant
- Neoprene bushing is oil and watertight

Ordering Information

Description	Form Size	Cable	UPC	Catalog Number
90° Male Thread, Liquidtight, for Insulated Cables	F3	.625"-1.750" (1.59-1.90)	783585497907	074011351

Listings

UL Listed  
CSA Certified


Specifications

Strand	Stainless Steel
Body	Nylon

Performance

Environmental	
Flammability	UL 94HB (Strand grip), UL 94V-2(Fitting)
Hazardous Locations	Suitable for use in hazardous locations per Class I Div. 2, Class II Div. 1 & 2, Class III Div. 1 & 2 N.E.C
Operating Temperatures	-40°F to +225°F (-40°C to +107°C)
Wet Locations	Suitable for use in wet locations when used with a listed sealing ring between box and fitting

HUBBELL

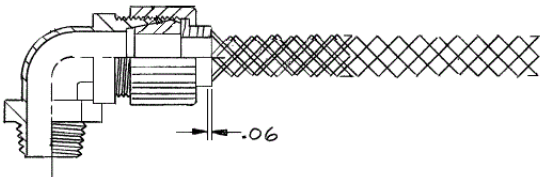

Related Products

Locknut	00322002LPK50
Metal Clad Sealing O-Ring	20509002

Online Resources

Customer Sales Drawings  
eCatalog

