

Kellems® Wire Management Products

PG and Metric Threaded Deluxe Cord Grips

Deluxe Cord Grips



- Features
- Aluminum Fiting
 - Stainless steel mesh is corrosion resistant
 - Neoprene bushing is oil and watertight

Ordering Information

Description	Hub Size	Cable	UPC	Catalog Number
Straight Metric Male Thread, Liquidtight	M32	1.125"-1.250" (2.86-3.17)	783585327891	074M321028

Listings

UL Listed


CSA Certified

Specifications

Strand	Stainless Steel
Body	Aluminum

Performance

Environmental	UL 94HB (Strand grip), UL 94V-2 (Fitting)
Flammability	Suitable for use in hazardous locations per Class I Div. 2, Class II Div. 1 & 2, Class III Div. 1 & 2 N.E.C
Hazardous Locations	
Operating Temperatures	-30°F to +240°F (-34°C to +115°C)
Wet Locations	Suitable for use in wet locations when used with a listed sealing ring between box and fitting

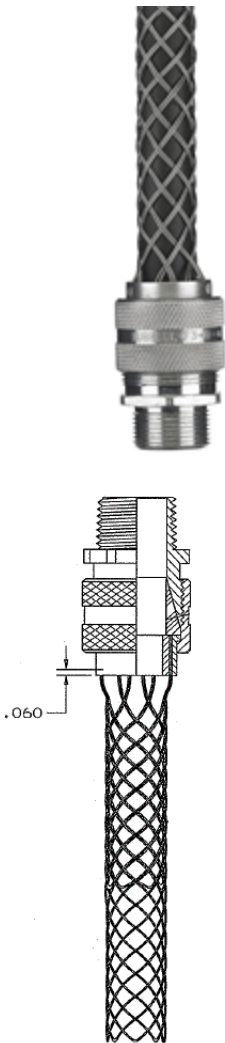

Related Products

Locknut	LNLM32BPK100
---------	--------------

Online Resources

Customer Sales Drawings

eCatalog

Installation Instructions

