

Straight Blade Devices 20A, 125V, 2 Pole, 3 Wire Grounding Hubbell-Pro™ Heavy Duty Duplex Receptacles

HUBBELL

Features

- Tamper-resistant shutter complies with national electrical code requirements
- Smooth face
- Triple wipe contacts
- Wrap-around galvanized steel strap

Ordering Information

| Description | Device Color | UPC | Catalog Number |
|---------------------|--------------|--------------|----------------|
| Back and side wired | Red | 783585582283 | 5352RTR |

Listings

UL File No. E2186
Certified to CSA 22.2, No. 42 File 285
Fed. Spec. W-C-596
NEMA® WD-6 Compliant

Specifications

| | |
|--------------------------|-------------------------|
| Material | Thermoplastic/Composite |
| Contacts | Brass |
| Mounting Strap | Galvanized steel |
| Automatic Self-grounding | Stainless steel |
| Staple | |
| Mounting Screws | Zinc plated steel |

Performance

Electrical


| | |
|----------------------|--|
| Current Interrupting | Certified for current interrupting at full rated current |
| Dielectric Voltage | Withstands 2,000V minimum |

Mechanical

| | |
|-------------------------|--|
| Product Identification | Ratings are a permanent part of the device |
| Terminal Accommodation | #12-#10 AWG copper stranded or solid conductor only |
| Terminal Identification | Terminal wire leads identified in accordance with UL 498 |

Environmental

| | |
|------------------------|---|
| Flammability | UL 94 V-2 |
| Operating Temperatures | Maximum continuous 75°C; minimum -40°C (w/o impact) |

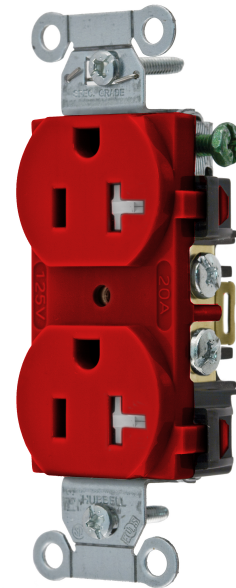

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

