

Watertight Devices
15A, 277V AC, 2 Pole, 3 Wire
Twist-Lock® Receptacles

HUBBELL

Features

- Impact resistant PBT lid, cover plate and receptacle body
- Thermoplastic elastomer seal
- Stainless steel assembly screws

Ordering Information

Description Receptacle	Device Color Yellow	UPC 783585184500	Catalog Number 65W34H
---------------------------	------------------------	---------------------	--------------------------

Listings

Listed to UL498
Certified to CSA C22.2 No. 42
Meets NEMA WD-1, WD-6 and ANSI standards

Specifications


Housing	PBT
Terminal Retainer	Clear polycarbonate
Contacts	Nickel plated brass
Terminal Screws	Steel, chromate
Lid and plate assembly	PBT
Assembly Screws	Stainless Steel

Performance

Electrical	
Current Interrupting	Rated for current interruption per UL498
Dielectric Voltage	2500V AC

Mechanical	
Terminal Accommodations	14 AWG to 10 AWG

Environmental	
Operating temperatures	-40°C (without impact) to +60°C continuous
UV resistance	All exposed materials are UV stabilized

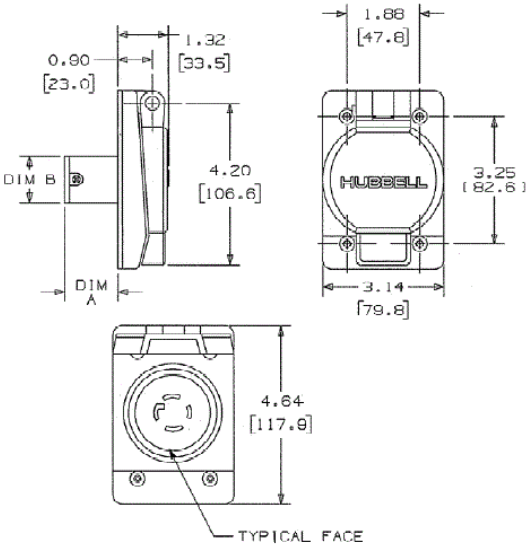

Resources

Customer Use Drawing
eCatalog

