

Straight Blade Devices

15A, 125V, 2 Pole, 3 Wire Grounding

Hubbell-PRO Heavy Duty Hospital Grade Receptacles

- Features
- Triple wipe contacts
  - High impact resistant face with circuit I.D. marking area
  - Steel mounting strap
  - Fully Controlled Device

Ordering Information


Description	Color	UPC	Catalog Number
Hospital grade, smooth face, back and side wired	Ivory	783585686257	8300C2IV

- Listings
- UL Listed to UL498 File No. E2193  
Certified to CSA, C22.2, No. 42 File 292  
Fed. Spec. W-C-603  
NEMA® WD-6 Compliant

Specifications	
Face	Nylon
Base	PBT
Power Contacts	Brass
Ground Contacts	Brass
Clamping Plate	Plated Steel
Mounting Strap	Galvanized Steel
Automatic Self-Grounding Staple	Stainless Steel
Mounting Screws	Zinc Plated Steel

Performance	
Electrical	
Current Interrupting	Certified for current interrupting at full rated current
Dielectric Voltage	Withstands 2,000V minimum
Mechanical	
Product Identification	Ratings are a permanent part of the device
Terminal Accomodation	14-#10 AWG copper stranded or solid conductor only
Terminal Identification	Terminals identified in accordance with UL 498 and CSA
Environmental	
Flammability	UL 94V-2
Operating Temperature	Maximum continuous 75°C; minimum -40°C (w/o impact)

HUBBELL

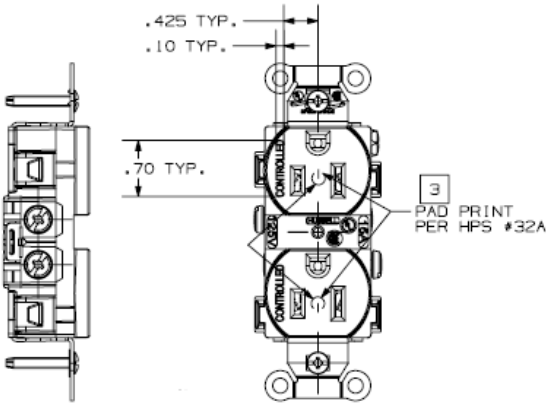

Related Products

Wallplate or Weatherproof CoverDuplex Opening

Online Resources

eCatalog

