

Straight Blade Devices

20A, 125V, 2 Pole, 3 Wire Grounding

Hubbell-PRO Heavy Duty Hospital Grade Receptacles

Features

- Triple wipe contacts
- High impact resistant face with circuit I.D. marking area
- Steel mounting strap
- Fully Controlled Device

Ordering Information

Description	Color	UPC	Catalog Number
Hospital grade, smooth face, back and side wired	White	783585530710	8300C2WHI

Listings

UL Listed to UL498 File No. E2192
Certified to CSA, C22.2, No. 42 File 291
Fed. Spec. W-C-602
NEMA® WD-6 Compliant


Specifications

Face	Nylon
Base	PBT
Power Contacts	Brass
Ground Contacts	Brass
Clamping Plate	Plated Steel
Mounting Strap	Galvanized Steel
Automatic Self-Grounding Staple	Stainless Steel
Mounting Screws	Zinc Plated Steel

Performance

Electrical	
Current Interrupting	Certified for current interrupting at full rated current
Dielectric Voltage	Withstands 2,000V minimum
Mechanical	
Product Identification	Ratings are a permanent part of the device
Terminal Accomodation	14-#10 AWG copper stranded or solid conductor only
Terminal Identification	Terminals identified in accordance with UL 498 and CSA
Environmental	
Flammability	UL 94V-2
Operating Temperature	Maximum continuous 75°C; minimum -40°C (w/o impact)

HUBBELL

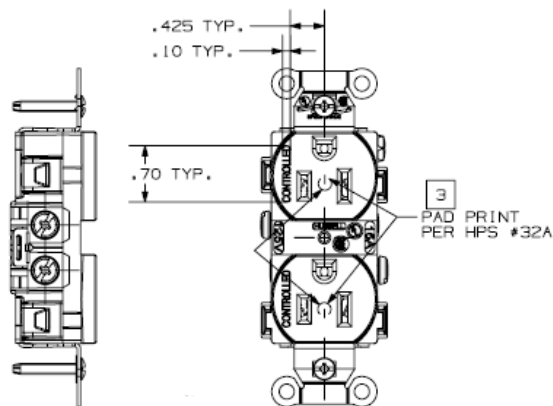

Related Products

Wallplate or Weatherproof CoverDuplex Opening

Online Resources

eCatalog
eCatalog

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

