

Floor Boxes


SystemOne ETERNAL™ Series Concrete Floorboxes

4-Gang Recessed

HUBBELL

Features

- 3.75" deep wiring chambers for large AV modules and feed-thru capacity
- External High Capacity Feed-Thru Hubs Sold Separately
- Stamped steel construction, ships with Flush Installation Cover & 1/2" Prepour Cover
- Pre and post pour adjustment
- Rectangular cover, patented labor saving easy mount device plates

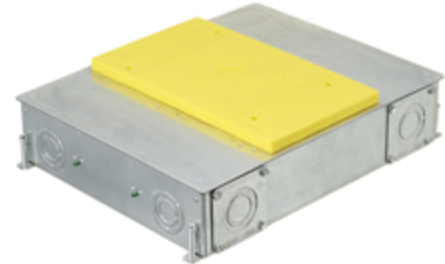

Ordering Information

Cover Style	Box Type	UPC	Catalog Number
Rectangular	Above Grade	783585695297	CFB4G30E

Listings

cULus Listed
UL 514A Listed

Specifications

Box Material	16 gauge galvanized steel
Box Finish	Natural
Top Mounting Plates	16 gauge galvanized steel
Flush Prepour Cover	16 gauge galvanized steel
1/2" Prepour Cover	Yellow Plastic
Device Chamber Grounding	6" Long #12 AWG Solid Copper Wire
Wiring Chamber Depth	3.75"
Wiring Chamber Volumes	(4) 51.0 IN ³ [835 CM ³]

Performance

Mechanical

Depth of Pour, Minimum	3.00" (76.2)
Depth of Pour, Recommended	3.50" (88.9)
Floor Box Cover Series	24Gxx
Floor Box Height	3.00"[76.2mm]
Floor Box Length	14.57" [370.1mm]
Floor Box Width	11.33" [287.8mm]
Trade Size Knock-Outs: Bottom	(4) 1/2", 3/4", 1", 1 1/4"
Trade Size Knock-Outs: Ends	(4) 1/2", 3/4", 1", 1 1/4"
Trade Size Knock-Outs: Sides	(4) 3/4", 1", 1 1/4", 2" (Field installed CFBHUB2 for 2" metallic conduit, CFBHUB200PVC for 2" PVC conduit or CFBHUB125PVC for 1 1/4" PVC conduit)

Related Products

(2) 2" PVC field installed hubs, ships with (2) 1-1/2" reducer, (2) 1-1/4" reducers, and (2) 1" reducers/plugs	CFBHUB200PVC
(2) 1-1/4" PVC field installed hubs, ships with (2) 1" reducers, (2) 3/4" reducers, AND (2) 1/2" reducer/plugs	CFBHUB125PVC
2" threaded zinc hub	CFBHUB2
Rectangular pre-pour 1/2 in. extension caps (2 pack)	24GEXTENDCAP2PK
3-Cubes, Single Circuit	PWFBMP3R

Online Resources

Customer Sales Drawings
eCatalog
Installation Instructions

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

