

Straight Blade Devices

15A, 125V, 2 Pole, 3 Wire Grounding

Commercial Specification Grade Duplex Receptacles



Features

- Tamper-resistant shutter complies with national electrical code requirements
- Smooth face
- Triple wipe contacts

Ordering Information

| Description | Device Color | UPC Number | Catalog Number |
|--|--------------|--------------|----------------|
| Tamper-Resistant, smooth face, side wired only | Black | 783585144207 | CR15BLKTR |

Listings

UL Listed to UL498 File No. E2186
Certified to CSA, C22.2, No. 42
NEMA® WD-6 Compliant

Specifications


| | |
|---------------------------------|-------------------------------|
| Face | Nylon |
| Base | Nylon |
| Power Contacts | .030 in. (.8) Brass |
| Mounting Strap | .040 in. (1) Galvanized steel |
| Terminal Screws | Plated steel |
| Automatic Self-grounding Staple | Stainless steel |
| Mounting Screws | Galvanized steel |

Performance

| | |
|-------------------------|--|
| Electrical | |
| Current Interrupting | Certified for current interrupting at full rated current |
| Dielectric Voltage | Withstands 2,000V minimum |
| Mechanical | |
| Product Identification | Ratings are a permanent part of the device |
| Terminal Accommodation | #14-#10 AWG copper stranded or solid conductor only |
| Terminal Identification | Terminals identified in accordance with UL 498 and CSA |
| Environmental | |
| Flammability | UL 94 V-2 |
| Operating Temperatures | Maximum continuous 75°C; minimum -40°C (w/o impact) |



15A 125V AC
NEMA 5-15R
UL CSA
0.5 HP

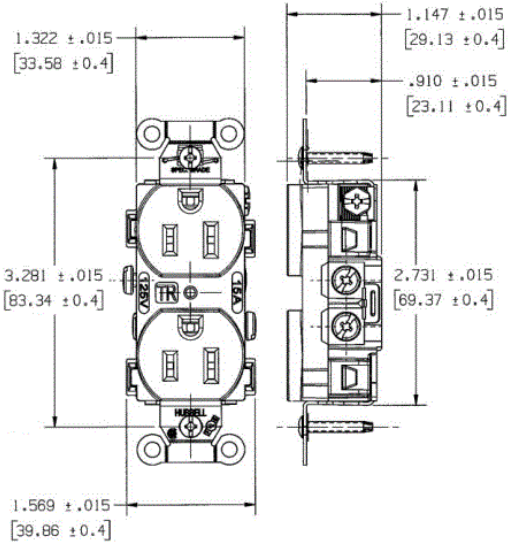

Complementary Products

| | |
|---------------------------------|----------------|
| Wallplate or Weatherproof Cover | Duplex Opening |
|---------------------------------|----------------|

Online Resources

Customer Sales Drawings
eCatalog

